




174-7123

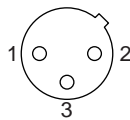

174-7124

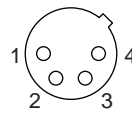

174-7125

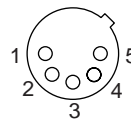

Specifications:

- Type: male
- Housing: zinc high pressure diecast
- Finish: satin nickel or black chrome
- Contacts: silver plated solid brass
- Pin base moldings: noryl (UL94V-1)
- Grommets: santoprene
- Collets: acetal
- Working voltage: 250VDC or AC peak
- Test voltage: 1500VAC
- Contact resistance: 3mΩ max.
- Temperature range: -30°C ~ +80°C

Mouser Stock No.	No. of Pins	Current Rating	Maximum Wire Gauge
174-7123	3	16A	12AWG
174-7124	4	10A	16AWG
174-7125	5	7.5A	18AWG

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Deltron:](#)

[709-0500](#) [709-0300](#) [709-0400](#) [713-0400](#)