


| REV | 1 | DATE        | ECN NUMBER | 2 | 3 | 4 | 5 | 6 | 7 |
|-----|---|-------------|------------|---|---|---|---|---|---|
| 003 |   | 23 Oct 2017 |            |   |   |   |   |   |   |
|     |   |             |            |   |   |   |   |   |   |

A standard in-line 4mm banana plug with a stainless steel contact spring.  
 The large rear diameter of this plug will accept cables with a conductor of up 5,5mm (10 awg).  
 The lead wire is held by soldering in a large solder bucket.

The product is also supplied with a large diameter insulating cover that accepts cables with a maximum outside diameter of 7,1mm. Silver plating Plug Body.

| Material       |                        |
|----------------|------------------------|
| Contact spring | Stainless steel, BS302 |
| Plug body      | Brass TR1 CZ 131       |
| Plug housing   | Acetal,C 27021 R       |
| Body plating   | Silver plating         |
| Rating         | 16 Amps                |
| Voltage        | 50 Volts MAX           |

### Dimensions

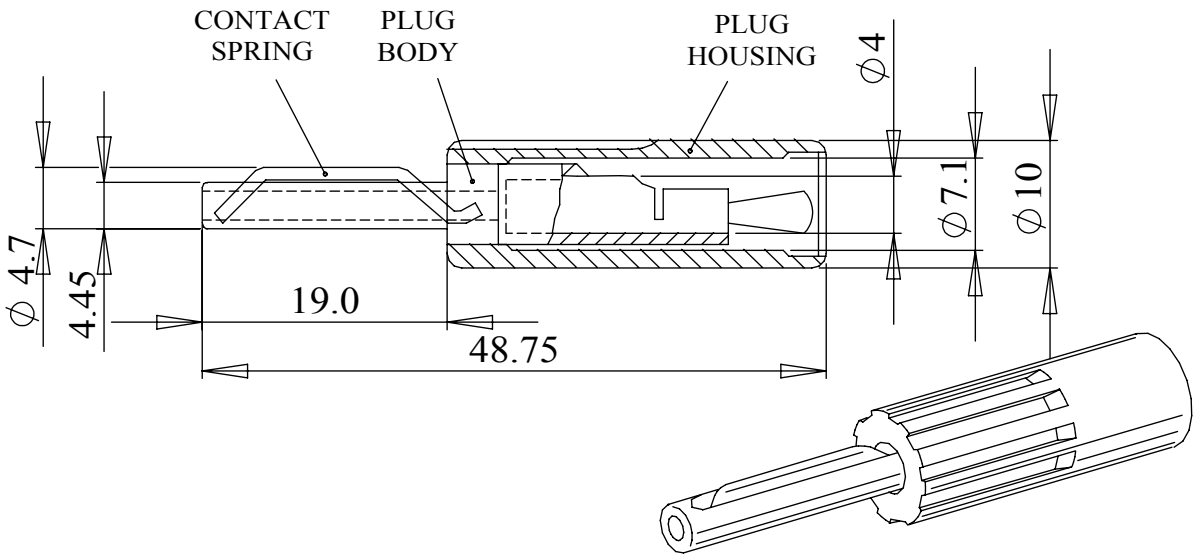

| Part No. | Colour & Plug Plating |                 |
|----------|-----------------------|-----------------|
| 579-0100 | BLACK                 | (Silver Plated) |
| 579-0200 | BLUE                  | (Silver Plated) |
| 579-0300 | BROWN                 | (Silver Plated) |
| 579-0400 | GREEN                 | (Silver Plated) |
| 579-0500 | RED                   | (Silver Plated) |
| 579-0600 | WHITE                 | (Silver Plated) |
| 579-0700 | YELLOW                | (Silver Plated) |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Deltron:

[579-0500](#) [579-0100](#) [579-0400](#) [579-0200](#)