



DeviceNet T-Connectors / Taps

0906 UTP 301




7/8" Male to 2 x 7/8" Female

Splitter/T-connector, with one 7/8" female, one 7/8" male, and one 7/8" female connectors, 5-poles - overmold color grey (standard).

— especially suitable for DeviceNet modules with 7/8" bus connection —


0906 UTP 301

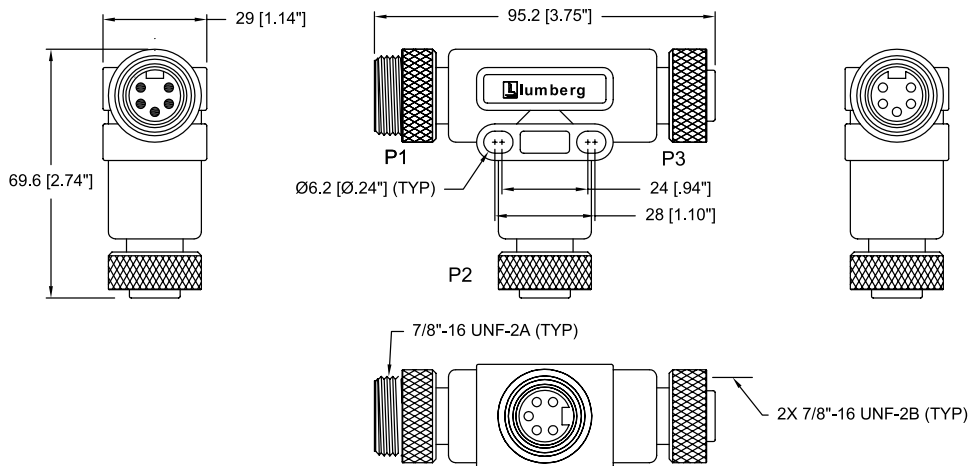


Pin Assignments

Face Views

7/8" - 5 poles

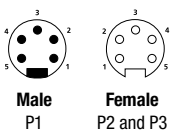

Wiring Diagrams

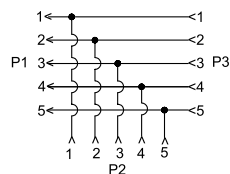



Be Certain with Belden

DeviceNet T-Connectors / Taps
0906 UTP 301

Technical Data

Environmental

Degree of protection IP 68 / NEMA 6P
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical

Housing / Molded body PUR, yellow
Insert PUR, yellow
Contact Solid-machined brass, gold over nickel plated
Coupling nut Aluminum, black anodized

Electrical

Current rating
P1 and P3: 8A (trunk)
P2: 4A (drop)
Voltage rating 300 V

Part Number	Pins	Characteristics
0906 UTP 301	5	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0906 UTP 301](#)