

Power Tee Tap, MINI 7/8"-M12


0906 UTP 318



M12 Female to 1 x 7/8" Male and 1 x 7/8" Female

Splitter/T-connector, with one M12 female, one 7/8" male and one 7/8" female connectors, 4-poles.

0906 UTP 318

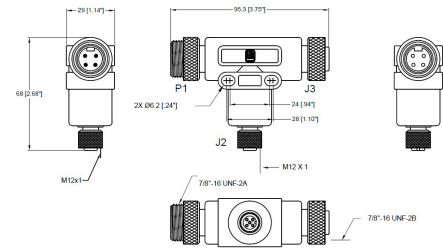


Pin Assignments

Face Views


M12 - 4 poles



 7/8" - 4 poles



Wiring Diagram

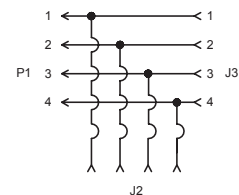

Be Certain with Belden

Power Tee Tap, MINI 7/8"-M12

0906 UTP 318

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical

Housing/Molded body TPU/yellow
Insert PUR
Contact CuZn alloy/gold over nickel or silver plated
Coupling nut (7/8"): Aluminum/black anodize, (M12): CuZn nickel plated
O-Ring (M12) NBR

Electrical

Rated current - 7/8 / M12 8A / 4A
Rated voltage 250 V

Part Number	Pins	Characteristics
0906 UTP 318	4	 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0906 UTP 318](#)