




0910 ASL 403



AS-Interface Module with 4-Digital Outputs

4 OUT

AS-Interface flat cable module with 4 digital outputs to connect standard actuators, combined M12 socket.

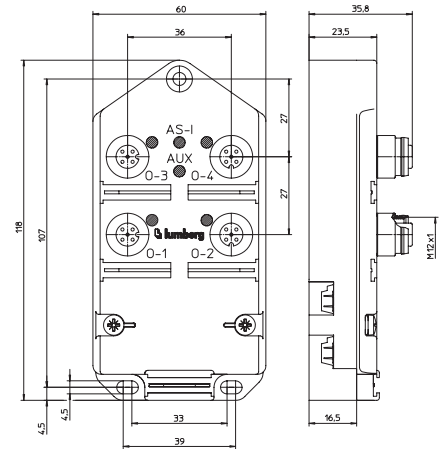

Bit Assignment

Bit	-	-	-	-	3	2	1	0
M12 Output								
Byte 0	-	-	-	-	0-4	0-3	0-2	0-1

Diagnostic Indication

LED	Indication	Condition
0-1..4	yellow	channel status
U-AS-i	green	AS-Interface power supply active
AUX	green	actuator supply active

Pin Assignments

Output M12

1	n.c.
2	n.c.
3	GND (0 V)
4	OUT
5	earth



Be Certain with Belden

AS-Interface Module with 4-Digital Outputs

0910 ASL 403

Technical Data

Environmental

Degree of protection	IP 67
Operating temperature range	-25°C (-13°F) to +80°C (+176°F)
Weight	200 g
Housing material	PUR

Bus system

AS-Interface profile	8.0
I/O configuration	8 hex
ID code	0 hex
Support A/B addressing	no

AS-Interface

Electronics power supply

Rated voltage	AS-Interface net
Voltage range	26.5–31.6 V DC
Power consumption	max. 75 mA
Reverse polarity protection	yes
Indication	LED green

AS-Interface

Output power supply

Rated voltage	24 V DC
Voltage range	10–30 V
Potential separation	present
Reverse polarity protection	yes/electronic
Indication	LED green

AUX

Outputs

Rated output current	Type 2 A acc. to IEC 61131-2-2
Short circuit-proof	2 A per channel
Max. output current	yes
Overload-proof	4 A per module
Number of digital channels	yes
Channel type N.O.	yes
Channel status indicator	4
	p-switching
	LED yellow per channel

Included in delivery / Accessories

Dust covers M12	2 pieces
Attachable label	10 pieces

Part Number

0910 ASL 403



The application of these products in harsh environments should always be checked before use.
Specifications subject to alteration.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0910 ASL 403](#)