 




0915 034 101/... M



AS-Interface cordset, double-ended, M12 male connector and M12 female connector with self-locking threaded joint.



AS-Interface Accessories

Technical Data

Environmental

Degree of protection	IP 67
Temperature range	-25°C / +80°C

Materials

Housing / Molded body	TPU, self-extinguishing
Insert	TPU, self-extinguishing
Contact Male connector:	CuZn, prenickel and 0.8 microns gold-plated
Female connector:	CuZn, prenickel and 0.3 microns gold-plated
Receptacle shell / knurled screw/ nut / hexagon screw/nut / sleeve	CuZn, nickel-plated
O-ring	FKM (only female connector)

Electrical data


Nominal current at 40°C	4 A
Nominal voltage	240 V
Rated voltage	250 V
Test voltage	2.0 kV eff. / 60 s
Insulation resistance	> 10 ⁹ Ω
Pollution degree	3

Cable specification

PUR/PVC - cable-no. 34
Further information please see chapter "Cable specifications"

Pin Assignments

4-Poles

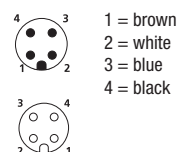

Part Number	Poles	Out Jacket	Standard Cable Lengths
0915 034 101/...M	4	PUR	1 M / 3 M / 5 M



The application of these products in harsh environments should always be checked before use.
Specifications subject to alteration.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[0915 034 101/3 M](#) [0915 034 101/1 M](#) [0915 034 101/5 M](#) [0915 034 101/2 M](#)