




0931 DNC 301



Passive DeviceNet Distribution Box


8 x M12

Passive DeviceNet distribution box, 7/8" Bus-In/
Bus-Out connection for Trunk line, 8 x M12
branches for Drop line.

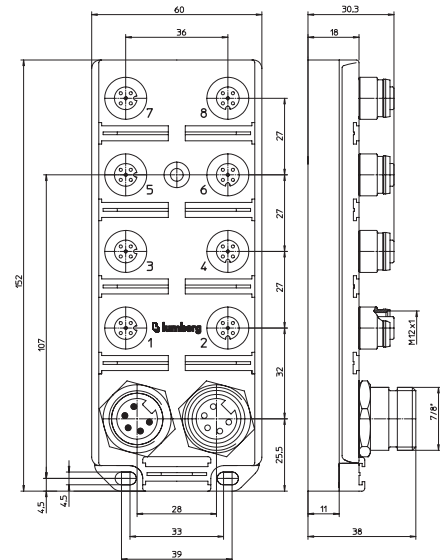


Pin Assignment

Bus connection 7/8"

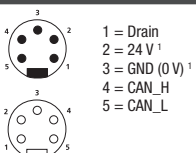

Branch M12

 



Be Certain with Belden

Passive DeviceNet Distribution Box

0931 DNC 301

Technical Data

Environmental

Degree of protection IP 67
Operating temperature range -10°C (+14°F) to +60°C (+140°F)

Mechanical

Weight 350 g
Housing material PUR
Total current max. 8 A / max. 3 A per M12 branch

Part Number

0931 DNC 301



The application of these products in harsh environments should always be checked before use.
Specifications subject to alteration.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0931 DNC 301](#)