



Be Certain with Belden

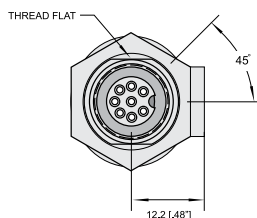

EtherMATE™ Industrial Ethernet PCB Receptacle

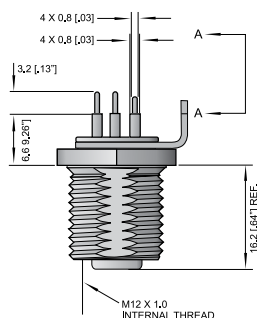

Type	0986 EFC 100
Product description	Receptacle connector, M12 female connector, 8-pole, PCB contacts with board lock.
Environmental	
Degree of protection	IP 67 / NEMA 6P
Operating temperature range	-25°C (-13°F) / +90°C (+194°F)
Mechanical	
Housing / Molded body	CuZn, nickel-plated
Pins	8
Insert	PUR, black
Contacts	CuZn, gold over nickel plated
O-ring	Viton
Board lock	Phosphor bronze, tin-lead plated
Electrical	
Current rating	4 A
Voltage rating	250 V

The application of these products in harsh environments should always be checked before use. Specifications subject to alteration.

Pin assignment	Recommended PCB pattern
M12, Female 8-poles	
Part number	Order number
0986 EFC 100	900000510



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0986 EFC 100](#)