

M12-Splitters/T-Connectors


ASBS 2 M12-S2326 | ASBS 2 M12-S2325
ASBS 2 M12-S1387 | ASBS 2 M12-S3995



M12 Male to 2xM12 Female

Splitter/T-connector, two way, 4-poles with one M12 male connector and two M12 female connectors.


ASBS 2 M12-S2326

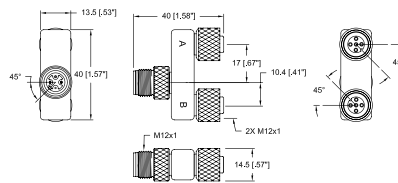


M12 Male to 2xM12 Female

Splitter/T-connector, two way, 5-poles with one M12 male connector and two M12 female connectors.


ASBS 2 M12-S2325

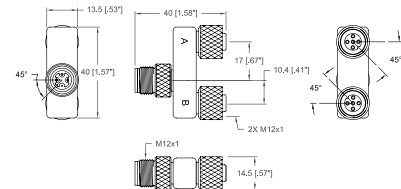

ASBS 2 M12-S1387

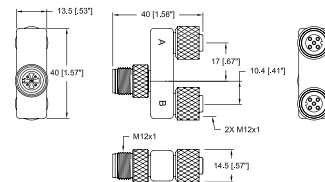

ASBS 2 M12-S3995

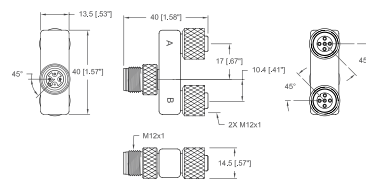

Pin Assignments

Face Views

ASBS 2 M12-S2326



A



B



ASBS 2 M12-S2325



A




B



Wiring Diagrams


ASBS 2 M12-S2326

WIRING SCHEMATIC

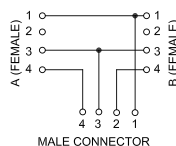


ASBS 2 M12-S2325

WIRING SCHEMATIC

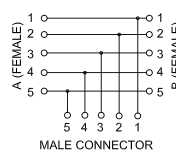


ASBS 2 M12-S1387

WIRING SCHEMATIC

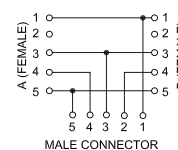

ASBS 2 M12-S3995

WIRING DIAGRAM

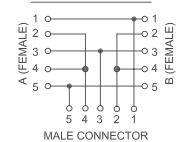



M12-Splitters/T-Connectors

ASBS 2 M12-S2326 | ASBS 2 M12-S2325 | ASBS 2 M12-S3187 | ASBS 2 M12-S3995

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -15°C (+5°F) / +90°C (+194°F)

Mechanical

Molded body PUR, black
Insert PUR, black
Contact Brass, gold over nickel plated
Coupling nut Brass, nickel-plated
O-ring FKM

Electrical

Contact resistance $\leq 5 \text{ m}\Omega$
Current rating 4 A
Voltage rating 250 V

Part Number	Pins	Characteristics
ASBS 2 M12-S2326	4	 
ASBS 2 M12-S2325	5	 
ASBS 2 M12-S3187	5	 
ASBS 2 M12-S3995	5	 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[ASBS 2 M12-S2325](#) [ASBS 2 M12-S3187](#) [ASBS 2 M12-S3995](#) [ASBS 2 M12-S2326](#)