



lumbergautomation

A **BELDEN** BRAND




0936 DMC 101 | 0936 DFC 101



5-Pole, Male

DeviceNet, 5-pole, male field attachable M12 connector with screw terminal connection, cable outlet suitable for THIN DeviceNet cable, DeviceNet color coding.


0936 DMC 101

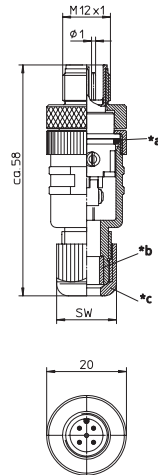

5-Pole, Female

DeviceNet, 5-pole, female field attachable M12 connector with screw terminal connection, cable outlet suitable for THIN DeviceNet cable, DeviceNet color coding.


0936 DFC 101

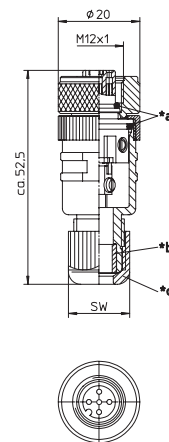

Pin Assignments

Face Views / M12

 5 pole





Be Certain with Belden

DeviceNet Field Attachable Connectors, M12
0936 DMC 101 | 0936 DFC 101

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -25°C (-13°F) / +90°C (+194°F)

Materials

Housing / Molded body PA
Insert PA
Contact CuZn, pre-coppered
Coupling nut CuZn, nickel-plated
O-ring FKM

Mechanical

Mode of connection Screw terminals
Connectable conductor max. 0.75 mm²

Electrical

Contact resistance ≤5mΩ
Current rating 4 A
Voltage rating 250 V

Part Number		Pins	Characteristics
0936 DMC 101		5	UL 
	0936 DFC 101	5	UL 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0936 DFC 101](#) [0936 DMC 101](#)