



DeviceNet Receptacles, M12


0936 DMC 151



5-Pole, Male

DeviceNet, 5-pole, male, M12 receptacle, 0.3 M leads, THIN specification, PG 9 thread for panel mount.

0936 DMC 151

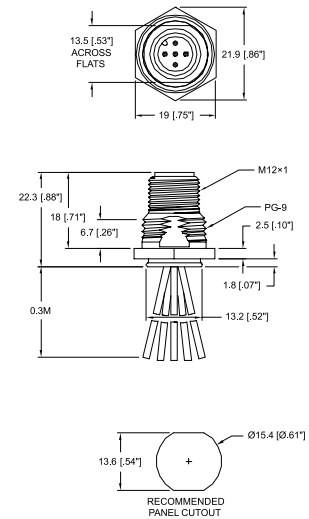

Pin Assignments

Face Views, M12

5 pole



- 1 = drain
- 2 = +24 V DC
- 3 = 0 V
- 4 = CAN_H
- 5 = CAN_L



Be Certain with Belden

DeviceNet Receptacles, M12
0936 DMC 151

Technical Data

Environmental	
Degree of protection	IP 67 / NEMA 6P
Operating temperature range	-40°C (-40°F) / +90°C (+194°F)

Mechanical	
Housing	Brass, nickel-plated
Insert	Polyamide, black
Contact	Brass, gold over nickel-plated
Panel nut	Brass, nickel plated

Electrical	
Current rating	4 A
Voltage rating	250 V

Wiring Specifications	
Conductor	22 AWG, stranded
Insulation	PVC
UL recognition	UL 1007

Part Number	Pins	Characteristics
Male		
0936 DMC 151	5	 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0936 DMC 151](#)