



0936 DMC 152




## DeviceNet Receptacles, M12

### 5-Pole, Male

DeviceNet, 5-pole, male M12 receptacle, assembled THIN cable, shielded, PG 9 thread for panel mount.

0936 DMC 152

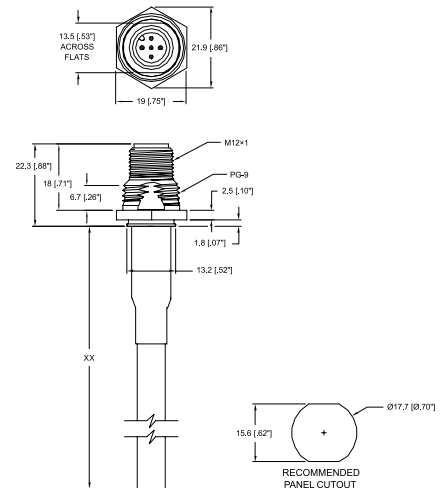

## Pin Assignments

Face Views, M12

5 pole



- 1 = drain
- 2 = +24 V DC
- 3 = 0 V
- 4 = CAN\_H
- 5 = CAN\_L



Be Certain with Belden

DeviceNet Receptacles, M12

0936 DMC 152

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P  
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical

Housing Brass, nickel-plated  
Insert 0936 DMC 152: PUR, yellow  
0936 DFC 152: PUR, black  
Contact Brass, gold over nickel-plated  
Panel nut Brass, nickel plated

Electrical

Current rating 4 A  
Voltage rating 250 V

Cable Specifications

Cable jacket PVC, grey  
Shielding Shielded  
Overall diameter .270"  
Conductor 1 Pair 22 AWG, 1 Pair 24 AWG  
Cable construction according to Devicenet THIN cable specification

Part Number	Pins	Cable Length	Characteristics
Male			
0936 DMC 152	5	2 M	 

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0936 DMC 152/2M](#)