



Be Certain with Belden

Profibus Signal Cables

0975 254 101 | 0975 254 102 | 0975 254 103



0975 254 101/...M

Double-ended cord set, M12 male connector to M12 female connector, 5 poles, B-coding.

0975 254 102/...M

Single-ended cord set, M12 male connector, 5 poles, B-coding.

0975 254 103/...M

Single-ended cord set, M12 female connector, 5 poles, B-coding.


0975 254 104



0975 254 104/...M

Double-ended cord set, M12 female connector, 5 poles, B-coding to SUBD male connector, 9 poles with switch-on terminating resistor.

0975 254 105

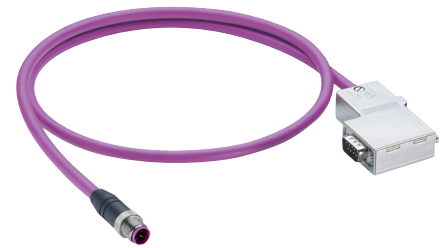


0975 254 105/...M

Double-ended cord set, M12 male connector, 5 poles, B-coding to SUBD male connector, 9 poles with switch-on terminating resistor.

Pin Assignment

M12 male/female connector, 5 poles

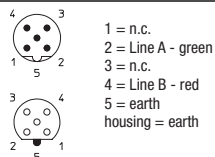

Part Number	Standard Cable Lengths	UL	RoHS	CE	REACH
0975 254 101/...M	0.3 M 0.6 M 1 M 2 M 3 M 5 M 10 M 15 M 20 M 25 M	UL	RoHS	CE	REACH
0975 254 102/...M	1 M 3 M 5 M 10 M 15 M	UL	RoHS	CE	REACH
0975 254 103/...M	1 M 3 M 5 M 10 M 15 M	UL	RoHS	CE	REACH
0975 254 104/...M	1 M 2 M 3 M 5 M	RoHS	CE	REACH	
0975 254 105/...M	1 M 2 M 3 M 5 M	RoHS	CE	REACH	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[0975 254 101/1 M](#) [0975 254 101/13 M](#) [0975 254 101/18 M](#) [0975 254 101/5 M](#) [0975 254 101/15 M](#) [0975 254 101/10 M](#) [0975 254 103/9 M](#) [0975 254 104/20 M](#) [0975 254 104/2 M](#) [0975 254 101/2 M](#) [0975 254 101/25 M](#) [0975 254 101/3 M](#) [0975 254 101/30 M](#) [0975 254 101/0,3 M](#) [0975 254 102/30 M](#) [0975 254 102/70 M](#) [0975 254 105/1 M](#) [0975 254 105/5 M](#) [0975 254 102/40 M](#) [0975 254 104/1 M](#) [0975 254 102/6 M](#) [0975 254 104/10 M](#) [0975 254 102/1 M](#) [0975 254 103/2 M](#) [0975 254 101/7 M](#) [0975 254 102/10 M](#) [0975 254 103/4.5 M](#) [0975 254 104/0,6 M](#) [0975 254 102/3 M](#) [0975 254 103/30 M](#) [0975 254 102/4 M](#) [0975 254 102/5 M](#) [0975 254 101/40 M](#) [0975 254 101/6 M](#) [0975 254 102/15 M](#) [0975 254 103/1 M](#) [0975 254 103/17 M](#) [0975 254 104/5 M](#) [0975 254 101/50 M](#) [0975 254 101/20 M](#) [0975 254 103/1,5 M](#) [0975 254 103/15 M](#) [0975 254 101/35 M](#) [0975 254 101/75 M](#) [0975 254 103/10 M](#) [0975 254 103/4 M](#) [0975 254 103/3 M](#) [0975 254 101/9 M](#) [0975 254 103/20 M](#) [0975 254 103/25 M](#) [0975 254 101/16 M](#) [0975 254 103/5 M](#) [0975 254 105/3 M](#) [0975 254 101/4 M](#) [0975 254 103/6 M](#) [0975 254 102/2 M](#) [0975 254 101/55 M](#) [0975 254 101/60 M](#) [0975 254 101/65 M](#) [0975 254 101/7,5 M](#) [0975 254 101/8 M](#) [0975 254 101/45 M](#) [0975 254 101/70 M](#) [0975 254 102/20 M](#) [0975 254 101/12 M](#) [0975 254 102/8 M](#) [0975 254 105/2 M](#) [0975 254 101/0,6 M](#)