





0976 PMC 501



PROFIBUS Field Attachable Connectors

SUBD Male (Screw Terminals)

Field attachable connector, SUBD male connector for Profibus, switch-on terminating resistor, 9 poles, assembling with screw terminals.

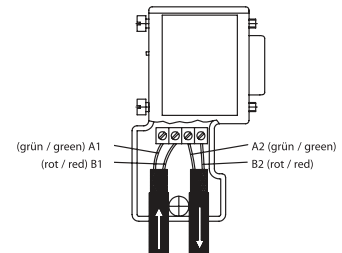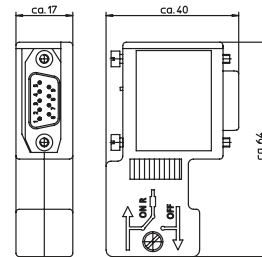



Be Certain with Belden

PROFIBUS Field Attachable Connectors
0976 PMC 501

Technical Data

Environmental

Degree of protection IP 40
Operating temperature range -0°C (-32°F) / +60°C (+140°F)

Mechanical

Housing / Molded body ABS, pre-coppered and nickel-plated
Contact CuZn, pre-nickel and gold-plated
Mode of connection screw terminals
Connectable conductor max. 1.0 mm²
Cable exit vertical

Electrical

Terminating resistor switch-on
Current consumption max. 12.5 mA
Nominal voltage 4.75–5.25 V DC
Transmission rate max. 12 MBit/s

Interfaces

Profibus device SUBD socket, 9 poles
Profibus bus cable 4 pole terminal block

Part Number	Pins
0976 PMC 501	9



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0976 PMC 501](#)