

1 1/8" Mini-Receptacle Connectors, Front Mount, US Color Code

RSF 90M...120M | RKF 901M...1201M




Male, 9-, 10-, and 12-Pole

Receptacle connector, 1 1/8"-c body, male
9-, 10-, and 12-pole for front mounting,
assembled stranded wire, potted with epoxy,
chassis side thread 1/2" NPT, screw connection.

- US Color Code -

RSF 90M...120M

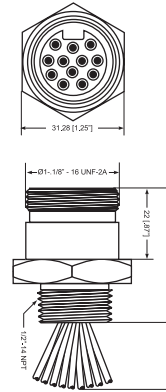


RKF 901M...1201M

Female, 9-, 10-, and 12-Pole

Receptacle connector, 1 1/8"-c body, female
9-, 10-, and 12-pole for front mounting,
assembled stranded wire, potted with epoxy,
chassis side thread 1/2" NPT, screw connection.


- US Color Code -

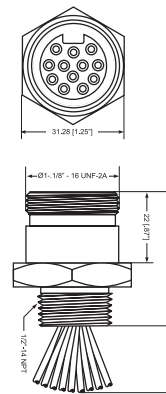

Pin Assignments


Face Views, 1 1/8"-Male / Female

 9 pole




- 1 = orange
- 2 = blue
- 3 = red with black tr.
- 4 = green with black tr.
- 5 = white
- 6 = red
- 7 = green
- 8 = white with black tr.
- 9 = black

 10 pole



- 1 = orange
- 2 = blue
- 3 = white/black
- 4 = red/black
- 5 = green/black
- 6 = orange/black
- 7 = red
- 8 = green
- 9 = black
- 10 = white

 12 pole



- 1 = orange
- 2 = blue
- 3 = white/black
- 4 = red/black
- 5 = green/black
- 6 = orange/black
- 7 = blue/black
- 8 = black/white
- 9 = green
- 10 = red
- 11 = white
- 12 = black












1 1/8" Mini-Receptacle Connectors, Front Mount, US Color Code
RSF 90M...120M | RKF 901M...1201M

Technical Data

Environmental
Degree of protection IP 68 / NEMA 6P
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical
Insert TPU, yellow
Contacts CuZn, gold plated
Receptacle shell Aluminum (anodized, clear)
Locknut Steel, zinc plated
O-ring Viton

Electrical
Current rating 9 and 10 pole: 7 A
12 pole: 5 A
Voltage rating 600 V

Part Number		Pins	Gauge	Characteristics
RSF 90M-623/1F	RKF 901M-623/1F	9	16	  
RSF 100M-699/1F	RKF 1001M-699/1F	10	16	  
RSF 120M-624/1F	RKF 1201M-624/1F	12	16	  

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RKF 1001M-699/12F](#) [RKF 1201M-624/15F](#) [RKF 1901M-669/10F](#) [RKF 1001M-699/10F](#) [RKF 1001M-699/1F](#) [RKF 1001M-699/3F](#) [RKF 1201M-676/6F](#) [RKF 1901M-669/6F](#) [RKF 190M-669/1F](#) [RKF 190M-669/3F](#) [RKF 190M-669/6F](#) [RKF 1201M-624/2F](#) [RKF 1201M-624/3F](#) [RKF 1201M-624/3M](#) [RKF 1201M-624/6F](#) [RKF 1201M-676/10F](#) [RKF 1201M-676/1F](#) [RKF 1201M-624/1F](#) [RKF 1001M-699/6F](#) [RKF 1901M-669/15F](#) [RKF 1901M-669/1F](#) [RKF 190M-669/15F](#)