

M12-Receptacle Connectors In Accordance With IEC 61076-2-101


RKF 4-693



Male, 4-Pole

Receptacle connector, female, front mounting,
18 AWG stranded copper conductors, 1/4"-18
NPT, EURO Color Code.


RKF 4-693

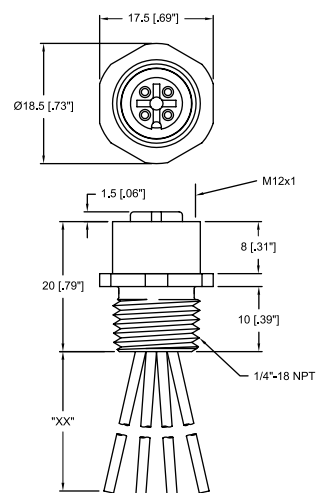

Pin Assignments

Face Views / M12, Female

 4 pole





M12-Receptacle Connectors In Accordance With IEC 61076-2-101
RKF 4-693

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -25°C (-13°F) / +90°C (+194°F)

Mechanical


Housing Brass, nickel-plated
Insert PUR, black
Contact Brass, gold over nickel-plated

Electrical

Current rating 4 A
Voltage rating 250 V

Wire Specifications

Conductors 18 AWG, stranded copper
Insulation PVC, 300V

Part Number	Pins	Leads AWG	Lead Lengths	Characteristics
RKF 4-693/...M	4	18 AWG	0.5 M / 2 M / 3 M	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[RKF 4-693/2M](#) [RKF 4-693/3M](#) [RKF 4-693/1M](#) [RKF 4-693/0.5M](#)