

M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101


RKT | RKWT



3-, 4-, 5-, 8-, and 12-Poles

Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, 8-, and 12-poles, female straight connector with self-locking thread and molded cable.


RKT

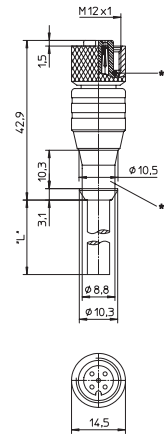

*a O-ring
*b Hose mounting

Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, 8-, and 12-poles, female 90° connector with self-locking thread and molded cable.

RKWT

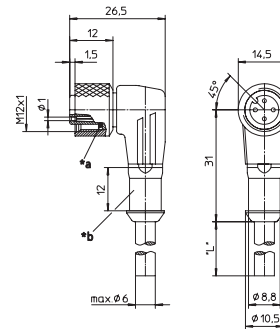


*a O-ring
*b Hose mounting


Pin Assignments

M12 - Male

 
3 poles




4 poles

 


5 poles

 


6 poles

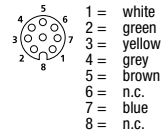

8 poles

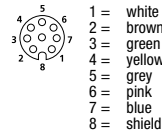

12 poles

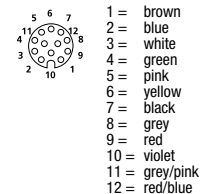



M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101

RKT | RKWT

Technical Data

Environmental

Degree of protection	IP 67 / NEMA 6P
Operating temperature range	-25°C (-13°F) / +80°C (+176°F)

Mechanical

Housing / Molded body	TPU
Insert	TPU
Contact	CuSn (12 poles: CuZn), pre-nickel and 0.3 microns gold-plated
Coupling nut	CuZn, nickel-plated
O-ring	FKM

Electrical

Contact resistance	≤ 5 mΩ
Nominal current at 40°C	3–5 poles 4 A, 6–12 poles 2 A
Rated voltage	3–4 poles 250 V 5 poles 63 V, 6–12 poles 36 V

Cable Specifications

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
06	PVC	3 x 0.34 mm²	Orange	.197" (5.0 mm)
07	PVC	4 x 0.25 mm²	Orange	.197" (5.0 mm)

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
56	PVC	5 x 0.34 mm²	Orange	.224" (5.7 mm)
224	PUR, halogen-free	3 x 0.34 mm²	Black	.169" (4.3 mm)
225	PUR, halogen-free	4 x 0.34 mm²	Black	.185" (4.7 mm)
228	PUR, halogen-free	5 x 0.50 mm²	Black	.213" (5.4 mm)
251	PUR, halogen-free welding spark proof	4 x 0.34 mm²	Orange	.185" (4.7 mm)
259	PUR, halogen-free welding spark proof	5 x 0.50 mm²	Orange	.217" (5.5 mm)
260	PUR, halogen-free welding spark proof	3 x 0.34 mm²	Orange	.177" (4.5 mm)
268	PUR, halogen-free welding spark proof	6 x 0.34 mm²	Orange	.236" (6.0 mm)
282	PUR, halogen-free	7 x 0.25 mm²	Black	.236" (6.0 mm)
337	PUR, halogen-free	6 x 0.34 mm²	Black	.236" (6.0 mm)
346	PUR, halogen-free	12 x 0.25 mm²	Black	.252" (6.4 mm)

Part Number		Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RKT 4-3-06/...M	RKWT 4-3-06/...M	3	PVC	2 M / 5 M / 10 M	 
RKT 4-3-224/...M	RKWT 4-3-224/...M		PUR, halogen-free	2 M / 5 M / 10 M	   
RKT 4-3-260/...M	RKWT 4-3-260/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	    
RKT 4-07/...M	RKWT 4-07/...M	4	PVC	2 M / 5 M / 10 M	 
RKT 4-225/...M	RKWT 4-225/...M		PUR, halogen-free	2 M / 5 M / 10 M	   
RKT 4-251/...M	RKWT 4-251/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	    
RKT 5-56/...M	RKWT 5-56/...M	5	PVC	2 M / 5 M / 10 M	 
RKT 5-228/...M	RKWT 5-228/...M		PUR, halogen-free	2 M / 5 M / 10 M	   
RKT 5-259/...M	RKWT 5-259/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	    
RKT 8-6-268/...M	RKWT 8-6-268/...M	6	PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	     
RKT 8-6-337/...M	RKWT 8-6-337/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	   
RKT 8-282/...M	RKWT 8-282/...M	8	PUR, halogen-free	2 M / 5 M / 10 M	   
RKT 12-346/...M	RKWT 12-346/...M	12	PUR, halogen-free	2 M / 5 M / 10 M	  

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RKT 12-346/10 M](#) [RKT 12-346/15 M](#) [RKT 12-346/2 M](#) [RKT 12-346/5 M](#) [RKT 4-07/25 M](#) [RKT 4-07/3 M](#) [RKT 4-3-224/10 M](#) [RKT 4-3-224/5 M](#) [RKT 8-6-337/2 M](#) [RKT 8-6-337/5 M](#) [RKT 8-282/10 M](#) [RKT 8-282/2 M](#) [RKT 8-282/5 M](#) [RKT 8-6-268/5 M](#) [RKT 4-251/5 M](#) [RKT 4-3-06/5 M](#) [RKT 4-3-224/15 M](#) [RKT 4-3-224/2 M](#) [RKT 5-228/10 M](#) [RKT 5-228/2 M](#) [RKT 5-228/5 M](#) [RKT 5-56/2 M](#) [RKT 5-56/5 M](#) [RKT 5-228/0,6 M](#) [RKT 5-228/1 M](#) [RKT 5-228/15 M](#) [RKT 4-225/60 M](#) [RKT 4-251/15 M](#) [RKT 5-228/30M](#) [RKT 5-259/2 M](#) [RKT 5-259/5 M](#) [RKT 5-56/1 M](#) [RKT 5-56/10 M](#) [RKT 5-56/3 M](#) [RKT 4-225/10 M](#) [RKT 4-225/2 M](#) [RKT 4-251/10 M](#) [RKT 5-228/20 M](#) [RKT 5-228/25 M](#) [RKT 5-228/3 M](#) [RKT 8-6-268/10 M](#) [RKT 8-6-268/2 M](#) [RKT 8-6-337/10 M](#) [RKT 4-07/10 M](#) [RKT 4-07/2 M](#) [RKT 4-07/5 M](#) [RKT 4-225/5 M](#) [RKT 8-282/15 M](#) [RKT 4-225/0,6 M](#) [RKT 4-225/15 M](#) [RKT 4-225/20 M](#) [RKT 4-225/25 M](#) [RKT 4-225/3 M](#) [RKT 4-225/40 M](#)