

M12-Round-Plug Connector, Single-Ended Cordsets, with LED


RKT/LED



3- and 4-Poles

Actuator/sensor cordset, single-ended, M12, 3- and 4-poles, Female straight connector with LED operation and function indicator with self-locking thread and molded cable.

RKT/LED

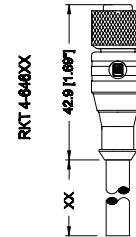


RKWT/LED



Actuator/sensor cordset, single-ended, M12, 3- and 4-poles, female 90° connector with LED operation and function indicator with self-locking thread and molded cable.


RKWT/LED

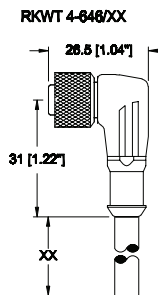


Pin Assignments

M12 - Female

 3 poles LED A




4 poles LED F

 


Wiring Diagram

 LED A



LED F

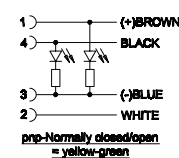

Be Certain with Belden

M12-Round-Plug Connector, Single-Ended Cordsets, with LED

Technical Data

Environmental

Degree of protection IP68 / Nema 6P
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical









Housing / Molded body PUR, translucent gray
Insert PUR, orange
Contact CuZn, gold-plated
Coupling nut CuZn, nickel-plated
O-ring FKM

Electrical

Current rating 4A
Voltage rating 10-30VDC

Cable Specifications

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
659	PVC	22 AWG	Gray	.190" (4.82 mm)
646	PVC	22 AWG	Gray	.190" (4.82 mm)

Part Number	Pins	LED	Standard Cable Lengths	Characteristics
RKT/LED A 4-3-659/...M	3	LED PNP	2M / 5M / 10M	 
RKWT/LED A 4-3-659/...M	3	LED PNP	2M / 5M / 10M	 
RKT/LED F 4-646/...M	4	LED PNP	2M / 5M / 10M	 
RKWT/LED F 4-646/...M	4	LED PNP	2M / 5M / 10M	 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RKT/LED A 4-3-659/2M](#) [RKT/LED A 4-3-659/5M](#) [RKT/LED F 4-646/10M](#) [RKT/LED F 4-646/2M](#) [RKT/LED F 4-646/5M](#)
[RKT/LED A 4-3-659/10M](#)