

Mini Single-Ended Cordsets

RKW 30-838



Description

MINI, Single-Ended Cordset, Right Angle, Female, 3 Pole, 16 AWG, PLTC, Yellow. TPE Cable, U.S. Color Code, IP 67 and NEMA 6P Rated.

Technical Data

Material

Molded body	TPU, yellow
Coupling nut	Aluminum, anodized black
Contacts	Brass, gold plated
Insert	TPE, yellow

Electrical

Current rating	8 A
Voltage rating	600 V

Mechanical

Temperature	-30°C to + 90°C
Protection	IP 67, NEMA 6P rated

Cable

Jacket	PUR, Yellow
Gauge	16 AWG
UL	TC-ER
Outside diameter	.315"

Part Number

RKW 30-838/1M


RKW 30-838/2M

RKW 30-838/3M

RKW 30-838/5M

RKW 30-838/10M

RKW 30-838/20M

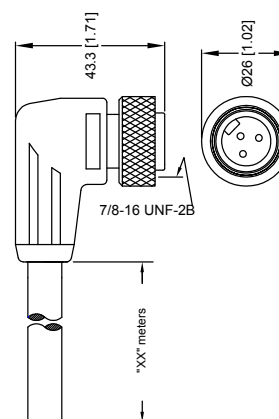

Pin Assignments

Face View 7/8"



1 = green
2 = black
3 = white



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RKW 30-838/30M](#) [RKW 30-838/5M](#) [RKW 30-838/4M](#) [RKW 30-838/2M](#) [RKW 30-838/10M](#) [RKW 30-838/1M](#) [RKW](#)
[30-838/20M](#) [RKW 30-838/15M](#) [RKW 30-838/3M](#) [RKW 30-838/25M](#) [RKW 30-838/6M](#)