

## M12-Round-Plug Connector, Single-Ended Cordsets, with LED


RKT/LED



### 3- and 4-Poles

Actuator/sensor cordset, single-ended, M12, 3- and 4-poles, Female straight connector with LED operation and function indicator with self-locking thread and molded cable.

RKT/LED

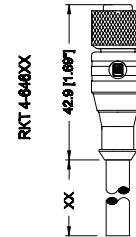


RKWT/LED



Actuator/sensor cordset, single-ended, M12, 3- and 4-poles, female 90° connector with LED operation and function indicator with self-locking thread and molded cable.


RKWT/LED

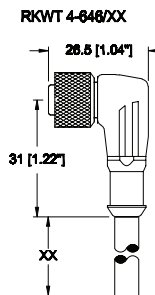


## Pin Assignments

### M12 - Female
 
#### 3 poles LED A




#### 4 poles LED F

 


### Wiring Diagram
 
#### LED A



#### LED F

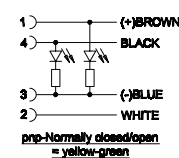

# Be Certain with Belden

## M12-Round-Plug Connector, Single-Ended Cordsets, with LED

### Technical Data

#### Environmental

Degree of protection	IP68 / Nema 6P
Operating temperature range	-40°C (-40°F) / +90°C (+194°F)

#### Mechanical









Housing / Molded body	PUR, translucent gray
Insert	PUR, orange
Contact	CuZn, gold-plated
Coupling nut	CuZn, nickel-plated
O-ring	FKM

#### Electrical

Current rating	4A
Voltage rating	10-30VDC

### Cable Specifications

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
659	PVC	22 AWG	Gray	.190" (4.82 mm)
646	PVC	22 AWG	Gray	.190" (4.82 mm)

Part Number	Pins	LED	Standard Cable Lengths	Characteristics
RKT/LED A 4-3-659/...M	3	LED PNP	2M / 5M / 10M	 
RKWT/LED A 4-3-659/...M	3	LED PNP	2M / 5M / 10M	 
RKT/LED F 4-646/...M	4	LED PNP	2M / 5M / 10M	 
RKWT/LED F 4-646/...M	4	LED PNP	2M / 5M / 10M	 

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[RKWT/LED F 4-646/10M](#) [RKWT/LED F 4-646/2M](#) [RKWT/LED F 4-646/5M](#)