

## Mini, 7/8"-Round-Plug Connector, Single-Ended Cordsets, EURO AC Color Code


RS 30 | RK 30



### 3-Poles


Mini, 7/8" single-ended cordsets, male straight, 3-poles with external threads and molded cable, EURO AC color code.

**RS**

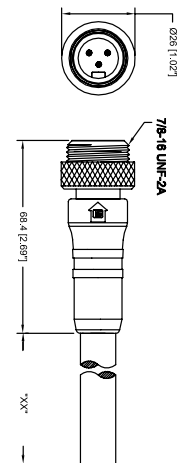

Mini, 7/8" single-ended cordsets, female straight, 3-poles with internal threads and molded cable, EURO AC color code.


**RK**

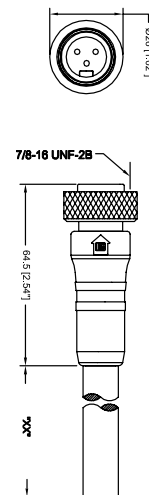

### Pin Assignments

Mini, 7/8" - Male / Female

 3 poles



1 = yellow/green  
2 = brown  
3 = blue

# Be Certain with Belden

Cordsets  
Single-Ended



Cordsets  
Single-Ended

## Mini, 7/8"-Round-Plug Connector, Single-Ended Cordsets, EURO AC Color Code RS 30 | RK 30

### Technical Data

#### Environmental

Degree of protection	IP 67 / NEMA 6P
Operating temperature range	-40°C (-40°F) / +90°C (194°F)

#### Mechanical

Housing / Molded body	TPU, yellow
Insert	TPU, yellow
Contact	CuZn, gold over silver plated
Coupling nut	Aluminum, anodized black

#### Electrical

Current rating	8 A
Voltage rating	300 V

### Cable Specifications - EURO AC Color Code

Cable No.	Outer Jacket	Gauge	Jacket Color	OD	Temperature Rating	Agency Approvals
601	PVC	18AWG	Yellow	.290" (7.4 mm)	-40°C (-40°F) to +105°C (221°F)	UL: AWM 2661 / CSA: AWM I/II A/B

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RS 30-601/...M    RK 30-60/...M	3	PVC	2 M / 5 M / 10 M	  

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[RS 30-601/10M](#) [RS 30-601/5M](#) [RS 30-601/2M](#)