


Mini Single-Ended Cordsets

RS 30-838 | RS 301-838

RS 30-838

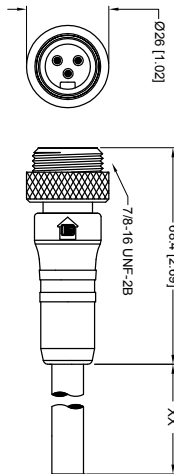

Description

MINI, Single-Ended Cordset, Straight, 3 Pole, 16 AWG, PLTC, Yellow. TPE Cable, U.S. Color Code, IP 67 and NEMA 6P Rated.

Technical Data

Material

Molded body	TPU, yellow
Coupling nut	Aluminum, anodized black
Contacts	Brass, gold plated
Insert	TPE, yellow

Electrical

Current rating	8 A
Voltage rating	600 V

Mechanical

Temperature	-30°C to + 90°C
Protection	IP 67, NEMA 6P rated


Cable

Jacket	PUR, Yellow
Gauge	16 AWG
UL	TC-ER
Outside diameter	.315"

Part Number

RS 30-838/1M
RS 30-838/2M
RS 30-838/3M
RS 30-838/5M
RS 30-838/10M
RS 30-838/20M
RS 301-838/1M
RS 301-838/2M
RS 301-838/3M
RS 301-838/5M
RS 301-838/10M
RS 301-838/20M

RS 301-838

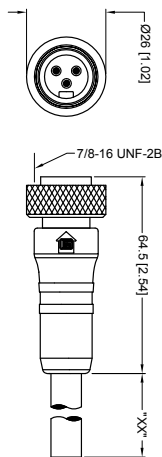

Pin Assignments

Face View 7/8"



- 1 = green
- 2 = black
- 3 = white



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RS 30-838/30M](#) [RS 30-838/5M](#) [RS 30-838/1M](#) [RS 30-838/25M](#) [RS 30-838/3M](#) [RS 30-838/15M](#) [RS 30-838/10M](#)
[RS 30-838/2M](#) [RS 30-838/20M](#)