

## Mini, 7/8" Field Attachable Connectors

### RSC 30-RSC 50 | RKC 30-RKC 50




#### Male, 3-, 4-, and 5-Pole

Field attachable connector, Mini, 7/8" male connector 3-, 4-, and 5-pole with threaded joint, assembling with screw terminals.

#### Female, 3-, 4-, and 5-Pole

Field attachable connector, Mini, 7/8" female

#### RSC 30-RSC 50

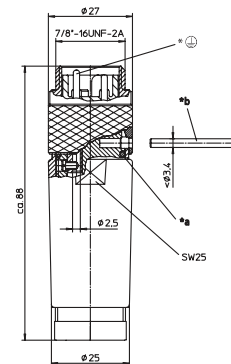


- \*a O-ring
- \*b Pin or screwdriver as assembly tool
- \*c Contact 1.5 leading



connector 3-, 4-, and 5-pole with threaded joint, assembling with screw terminals.

#### RKC 30-RKC 50

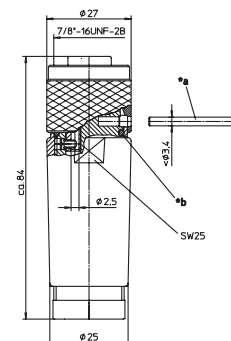

- \*a O-ring
- \*b Pin or screwdriver as assembly tool


## Pin Assignments
 
### Mini, 7/8" - Male / Female


#### 3 poles



#### 4 poles



#### 5 poles

 

# Be Certain with Belden

## Mini, 7/8" Field Attachable Connectors

RSC 30-RSC 50 | RKC 30-RKC 50

### Technical Data

#### Environmental













Degree of protection IP 67 / NEMA 6P  
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

#### Mechanical

Housing / Molded body PA  
Insert TPU, self-extinguishing  
Contact CuZn, gold over nickel plated  
Coupling nut Al anodized  
O-ring NBR  
Mode of connection screw terminals  
Connectable conductor max. 1.5 mm<sup>2</sup>

#### Electrical

Contact resistance ≤ 5 mΩ  
Nominal current at 40°C 3 poles 12 A  
4–5 poles 9 A  
Nominal voltage 240 V  
Rated voltage 250 V  
Test voltage 3 poles 2.5 kV eff. / 60 s  
4–5 poles 1.5 kV eff. / 60 s  
Insulation resistance > 10<sup>9</sup> Ω  
Pollution degree 3

Part Number		Pins	Cable Diameter Range	Characteristics
Male	Female			
RSC 30/9	RKC 30/9	3	Ø 6.0 – 8.0 mm	
RSC 30/11	RKC 30/11		Ø 8.0 – 10.0 mm	
RSC 30/13.5	RKC 30/13.5		Ø 10 – 12.0 mm	
RSC 30/16	RKC 30/16		Ø 12 – 14.0 mm	
RSC 40/9	RKC 40/9	4	Ø 6.0 – 8.0 mm	
RSC 40/11	RKC 40/11		Ø 8.0 – 10.0 mm	
RSC 40/13.5	RKC 40/13.5		Ø 10 – 12.0 mm	
RSC 40/16	RKC 40/16		Ø 12 – 14.0 mm	
RSC 50/9	RKC 50/9	5	Ø 6.0 – 8.0 mm	
RSC 50/11	RKC 50/11		Ø 8.0 – 10.0 mm	
RSC 50/13.5	RKC 50/13.5		Ø 10.0 – 12.0 mm	
RSC 50/16	RKC 50/16		Ø 12.0 – 14.0 mm	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Lumberg Automation:

[RSC 50/11 single pk of 1](#) [RSC 40/16 single pk of 1](#) [RSC 40/9 single pk of 1](#) [RSC 50/9 single pk of 1](#) [RSC 30/13.5 single pk of 1](#) [RSC 30/16 single pk of 1](#) [RSC 30/11 single pk of 1](#) [RSC 40/11 single pk of 1](#) [RSC 30/9 single pk of 1](#) [RSC 40/13.5 single pk of 1](#) [RSC 50/13.5 single pk of 1](#) [RSC 50/16 single pk of 1](#)