

M12 Field Attachable Connectors

RSCQS | 0976 PMC 102 | 0986 EMC 102
RKCQS | 0976 PFC 102




Male, 3- and 4-Pole

Field attachable connector, M12 male connector, 3- and 4-pole with threaded joint, shieldable, assembling with spring-type terminals.

- 0976 PMC 102: 4 poles, B coding, especially suitable for Profibus signal cable 0975 254 000/...M –
- 0986 EMC 102: 4 poles, D coding, especially suitable for Industrial Ethernet data cable 0985 342 000/... M –

RSCQS | 0976 PMC 102 | 0986 EMC 102

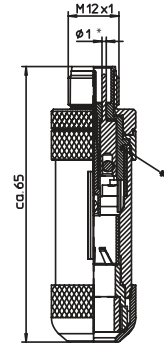

*a O-Ring




Female, 3- and 4-Pole

Field attachable connector, M12 female connector, 3- and 4-pole with threaded joint, shieldable, assembling with spring-type terminals.

- 0976 PFC 102: 4 poles, B coding, especially suitable for Profibus signal cable 0975 254 000/... M –

RKCQS | 0976 PFC 102

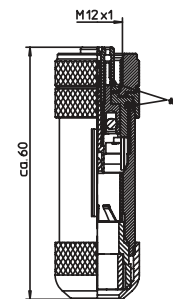

*a O-Ring

Pin Assignments

Face Views / M12, Male / Female

 
3 pole



4 pole



4 pole B-coding



4 pole D-coding





Be Certain with Belden

M12 Field Attachable Connectors

RSCQS | 0976 PMC 102 | 0986 EMC 102 | RKCQS | 0976 PFC 102

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -25°C (-13°F) / +90°C (+194°F)

Mechanical

Housing / Molded body GD-ZnAl, pre-coppered and nickel-plated
Insert PBT
Contact Stainless steel, silver-plated, gold-plated
Receptacle shell CuZn, nickel-plated
Shield sleeve CuBe, tin-plated
O-ring FKM
Mode of connection Spring-type terminals
Connectable conductor 0.14–0.50 mm², 0.14 mm² with terminal pin sleeve

Electrical

Contact resistance ≤ 5 mΩ
Nominal current at 40°C 4 A
Nominal voltage 120 V
0976 PMC 102: 32 V
Rated voltage 125 V
Test voltage 1.5 kV eff. / 60 s
0976 PMC 102: 0.65 kV eff. / 60 s
Insulation resistance > 10⁹ Ω
Pollution degree 3

Part Number		Pins	Cable Diameter Range	Characteristics
Male	Female			
RSCQS 3/9	RKCQS 4/3/9	3	Ø 4.0–9.0 mm	 
RSCQS 4/9	RKCQS 4/9	4	Ø 4.0–9.0 mm	 
0976 PMC 102	0976 PFC 102	4B	Ø 4.0–9.0 mm	 
0976 EMC 102		4D	Ø 4.0–9.0 mm	 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[RSCQS 3/9 single pk of 1](#) [RSCQS 4/9 single pk of 1](#)