

M12-Round-Plug Connector, Double-Ended Cordsets, with LED


RST-RKT/LED | RST-RKWT/LED



3- and 4-Poles


Actuator/sensor cordset, double-ended, M12, 3- and 4-poles, male straight to female straight connector with self-locking thread and molded cable.

RST-RKT/LED

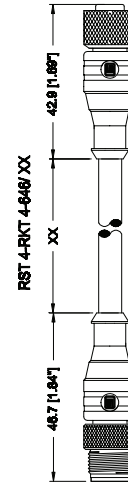

Actuator/sensor cordset, double-ended, M12, 3- and 4-poles, male straight to female 90° connector with self-locking thread and molded cable.


RST-RKWT/LED

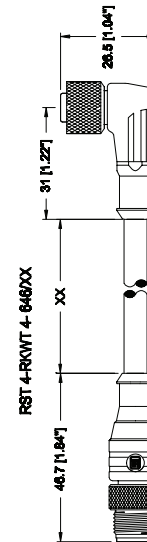


Pin Assignments

M12

3 poles LED A

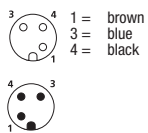


4 poles LED F

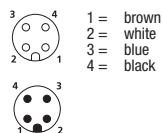


Wiring Diagram

 LED A



LED F

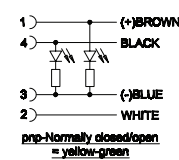

Be Certain with Belden

M12-Round-Plug Connector, Double-Ended Cordsets, with LED

Technical Data

Environmental

Degree of protection	IP68 / Nema 6P
Operating temperature range	-40°C (-40°F) / +90°C (+194°F)

Mechanical









Housing / Molded body	PUR, translucent gray
Insert	PUR orange
Contact	CuZn, gold-plated
Coupling nut	CuZn, nickel-plated
O-ring	FKM

Electrical

Current rating	4A
Voltage rating	10-30VDC

Cable Specifications

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
659	PVC	22 AWG	Gray	.190" (4.82 mm)
646	PVC	22 AWG	Gray	.190" (4.82 mm)

Part Number	Pins	LED	Standard Cable Lengths	Characteristics
RST 3-RKT/LED A 4-3-659/...M	3	LED PNP	0.6M / 1M / 2M / 5M	 
RST 3-RKWT/LED A 4-3-659/...M	3	LED PNP	0.6M / 1M / 2M / 5M	 
RST 4-RKT/LED F 4-646/...M	4	LED PNP	0.6M / 1M / 2M / 5M	 
RST 4-RKWT/LED F 4-646/...M	4	LED PNP	0.6M / 1M / 2M / 5M	 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RST 4-RKT/LED F 4-646/5M](#) [RST 3-RKWT/LED A 4-3-659/1M](#) [RST 4-RKWT/LED F 4-646/1M](#) [RST 3-RKT/LED A 4-3-659/5M](#) [RST 4-RKWT/LED F 4-646/2M](#) [RST 4-RKWT/LED F 4-646/0.6M](#) [RST 3-RKWT/LED A 4-3-659/2M](#) [RST 4-RKT/LED F 4-646/2M](#) [RST 4-RKWT/LED F 4-646/5M](#) [RST 3-RKWT/LED A 4-3-659/0.6M](#) [RST 3-RKT/LED A 4-3-659/0.6M](#) [RST 4-RKT/LED F 4-646/1M](#) [RST 3-RKT/LED A 4-3-659/1M](#) [RST 3-RKT/LED A 4-3-659/2M](#) [RST 4-RKT/LED F 4-646/0.6M](#) [RST 3-RKWT/LED A 4-3-659/5M](#)