


1/2"-20-Round-Plug Connector, Double-Ended Cordsets, US Color Code


RST...U-RKT ...U | RST...U-RKWT...U

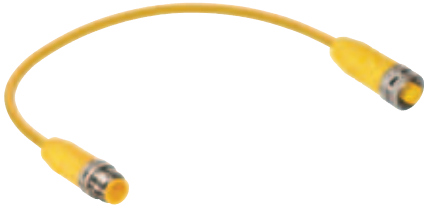

3-Poles


1/2"-20 actuator/sensor-cordsets, double ended, 3-poles, male to female straight connector, dual keyway, 18 gauge, US color code.

RST...U-RKT...U

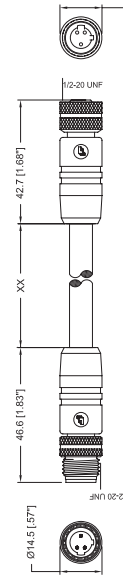

1/2"-20 actuator/sensor-cordsets, single ended, 3-poles, male to female 90° connector, dual keyway, 18 gauge, US color code.


RST...U-RKWT...U

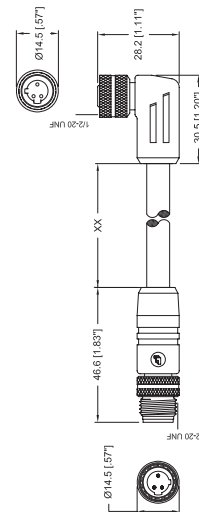


Pin Assignments

1/2"-20 - Male / Female

 3 poles



1 = green
2 = black
3 = white

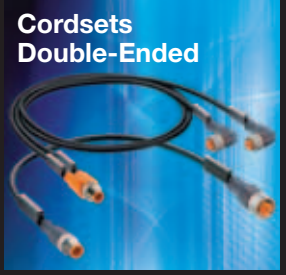

1/2"-20-Round-Plug Connector, Double-Ended Cordsets, US Color Code
RST...U-RKT...U | RST...U-RKWT...U

Technical Data

Environmental

Degree of protection	IP 67 / NEMA 6P
Operating temperature range	-40°C (-40°F) / +90°C (+194°F)

Mechanical

Housing / Molded body	TPU, yellow
Insert	TPU, yellow
Contact	CuZn, gold over nickel plated
Coupling nut	CuZn, nickel-plated

Electrical

Current rating	4 A
Voltage rating	250 V

Cable Specifications - US Color Code

Cable No.	Outer Jacket	Gauge	Conductor Size	Jacket Color	OD
619	CPE	18AWG	3 x 0.75mm ²	Yellow	.370" (9.4 mm)

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RST 3U-RKT 3U-619/...F RST 3U-RKWT 3U-619/...F	3	CPE	3 F / 6 F / 12 F / 15 F	  

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RST 3 U-RKT 3 U-619/1.5F](#) [RST 3 U-RKT 3 U-619/15F](#) [RST 3 U-RKWT 3 U-619/6F](#) [RST 3 U-RKWT 3 U-619/15F](#)
[RST 3 U-RKT 3 U-619/3F](#) [RST 3 U-RKWT 3 U-619/9F](#) [RST 3 U-RKT 3 U-619/12F](#) [RST 3 U-RKT 3 U-619/6F](#) [RST 3](#)
[U-RKWT 3 U-619/3F](#) [RST 3 U-RKWT 3 U-619/20F](#) [RST 3 U-RKWT 3 U-619/12F](#)