


RST...U-RKT ...U | RST...U-RKWT...U



3, 4-, and 5-Poles


1/2"-20 actuator/sensor cordsets, double-ended, 3-, 4- and 5-Poles, male to female straight connector, dual keyway, 18 and 22 gauge, Automotive color code.

RST...U-RKT...U

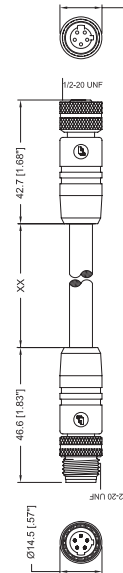

1/2"-20 actuator/sensor cordsets, double-ended, 3-, 4- and 5-Poles, male to female 90° connector, dual keyway, 18 and 22 gauge, Automotive color code.


RST...U-RKWT...U

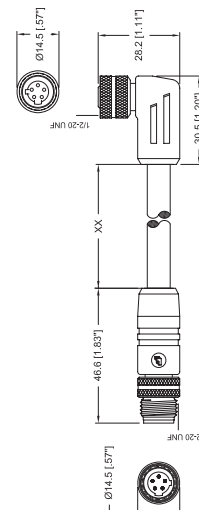

Pin Assignments


1/2"-20 - Male / Female

 3 poles




1 = green
2 = red/black
3 = red/white

 4 poles



1 = red/black
2 = red/white
3 = red
4 = green

 5 poles



1 = red/white tr.
2 = red
3 = green
4 = red/yel tr.
5 = red/blk tr.



Be Certain with Belden

1/2"-20-Round-Plug Connector, Single-Ended Cordsets, Automotive Color Code

RST...U-RKT...U | RST...U-RKWT...U

Technical Data

Environmental

Degree of protection IP 67 / NEMA 6P
Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical

Housing / Molded body TPU, yellow
Insert TPU, yellow
Contact CuZn, gold over nickel plated
Coupling nut CuZn, nickel-plated

Electrical

Current rating 4 A
Voltage rating 250 V

Cable Specifications - Automotive Color Code

Cable No.	Outer Jacket	Gauge	Conductor Size	Jacket Color	OD
688	PVC	18AWG	3 x 0.75mm ²	Yellow	.290" (7.4 mm)
689	PVC	18AWG	4 x 0.75mm ²	Yellow	.290" (7.4 mm)
755	TPE	18AWG	5 x 0.75mm ²	Yellow	.333" (8.5 mm)
618	PVC	22AWG	3 x 0.34mm ²	Yellow	.180" (4.6 mm)
674	PVC	22AWG	4 x 0.34mm ²	Yellow	.190" (4.8 mm)
673	PVC	22AWG	5 x 0.34mm ²	Yellow	.210" (5.3 mm)
664	PUR	22AWG	3 x 0.34mm ²	Yellow	.190" (4.8 mm)

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RST 3U-RKT 3U-688/...F	3	PVC	3 F / 6 F / 12 F / 15 F	  
RST 4U-RKT 4U-689/...F	4	PVC	3 F / 6 F / 12 F / 15 F	  
RST 5U-RKT 5U-755/...F	5	TPE	3 F / 6 F / 12 F / 15 F	  
RST 3U-RKT 3U-618/...F	3	PVC	3 F / 6 F / 12 F / 15 F	  
RST 4U-RKT 4U-674/...F	4	PVC	3 F / 6 F / 12 F / 15 F	  
RST 5U-RKT 5U-673/...F	5	PVC	3 F / 6 F / 12 F / 15 F	  
RST 3U-RKT 3U-664/...F	3	PUR	3 F / 6 F / 12 F / 15 F	  

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumberg Automation:

[RST 5 U-RKWT 5 U-673/100F](#) [RST 5 U-RKWT 5 U-673/6F](#) [RST 5 U-RKT 5 U-673/10F](#) [RST 4 U-RKT 4 U-674/15F](#)
[RST 4 U-RKT 4 U-689/3F](#) [RST 5 U-RKWT 5 U-673/65F](#) [RST 5 U-RKT 5 U-673/3F](#) [RST 4 U-RKT 4 U-674/3F](#) [RST 5](#)
[U-RKT 5 U-673/12F](#) [RST 5 U-RKT 5 U-673/15F](#) [RST 4 U-RKT 4 U-689/6F](#) [RST 5 U-RKT 5 U-755/6F](#) [RST 5 U-RKWT](#)
[5 U-673/3F](#) [RST 5 U-RKWT 5 U-673/50F](#) [RST 4 U-RKT 4 U-689/12F](#) [RST 5 U-RKT 5 U-755/15F](#) [RST 5 U-RKT 5 U-](#)
[673/20F](#) [RST 5 U-RKWT 5 U-673/15F](#) [RST 5 U-RKWT 5 U-673/10F](#) [RST 5 U-RKT 5 U-755/3F](#) [RST 4 U-RKT 4 U-](#)
[689/15F](#) [RST 5 U-RKT 5 U-673/6F](#) [RST 5 U-RKT 5 U-755/12F](#) [RST 5 U-RKWT 5 U-673/20F](#) [RST 5 U-RKT 5 U-](#)
[673/65F](#) [RST 4 U-RKT 4 U-674/12F](#) [RST 5 U-RKWT 5 U-673/12F](#) [RST 5 U-RKT 5 U-673/50F](#) [RST 4 U-RKT 4 U-](#)
[674/6F](#) [RST 4 U-RKWT 4 U-674/12F](#) [RST 4 U-RKWT 4 U-674/3F](#) [RST 5 U-RKT 5 U-673/100F](#)