

M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101


RST



3-, 4-, 5-, and 8-Poles

Actuator/sensor cordset, single-ended, M12,
3-, 4-, 5-, and 8-poles, male straight connector
with self-locking thread and molded cable.

RST

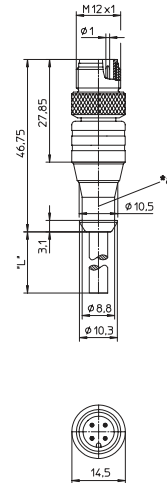


*a hose mounting


Pin Assignments

M12 - Male

 
3 poles




4 poles

 

5 poles

 

8 poles

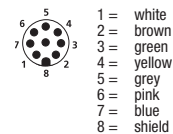

Be Certain with Belden

M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101 RST

Technical Data

Environmental

Degree of protection	IP 67 / NEMA 6P
Operating temperature range	-25°C (-13°F) / +80°C (+176°F)

Mechanical

Housing / Molded body	TPU
Insert	TPU
Contact	CuSn, pre-nickel and 0.3 microns gold-plated
Coupling nut	CuZn, nickel-plated

Electrical

Contact resistance	≤ 5 mΩ
Nominal current at 40°C	3–5 poles 4 A 8 poles 2 A
Nominal voltage	3–4 poles 240 V 5 poles 60 V 8 poles 30 V
Rated voltage	3–4 poles 250 V 5 poles 63 V 8 poles 36 V
Test voltage	3–4 poles 2.0 kV eff. / 60 s 5–8 poles 1.5 kV eff. / 60 s
Insulation resistance	> 10 ⁹ Ω
Pollution degree	3

Cable Specifications

Cable No.	Outer Jacket	Conductor Size	Jacket Color	OD
06	PVC	3 x 0.34 mm ²	Orange	.197" (5.0 mm)
07	PVC	4 x 0.75 mm ²	Orange	.197" (5.0 mm)
56	PVC	5 x 0.34 mm ²	Orange	.224" (5.7 mm)
224	PUR, halogen-free	3 x 0.34 mm ²	Black	.169" (4.3 mm)
225	PUR, halogen-free	4 x 0.34 mm ²	Black	.185" (4.7 mm)
228	PUR, halogen-free	5 x 0.50 mm ²	Black	.213" (5.4 mm)
251	PUR, halogen-free welding spark proof	4 x 0.34 mm ²	Orange	.185" (4.7 mm)
259	PUR, halogen-free welding spark proof	5 x 0.50 mm ²	Orange	.217" (5.5 mm)
260	PUR, halogen-free welding spark proof	3 x 0.34 mm ²	Orange	.177" (4.5 mm)
282	PUR, halogen-free	7 x 0.25 mm ²	Black	.236" (6.0 mm)
344	PUR, halogen-free	7 x 0.25 mm ²	Black	.236" (6.0 mm)

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RST 3-06/...M	3	PVC	2 M / 5 M / 10 M	
RST 3-224/...M		PUR, halogen-free	2 M / 5 M / 10 M	
RST 3-260/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	
RST 4-07/...M	4	PVC	2 M / 5 M / 10 M	
RST 4-225/...M		PUR, halogen-free	2 M / 5 M / 10 M	
RST 4-251/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	
RST 5-56/...M	5	PVC	2 M / 5 M / 10 M	
RST 5-228/...M		PUR, halogen-free	2 M / 5 M / 10 M	
RST 5-259/...M		PUR, halogen-free / welding spark proof	2 M / 5 M / 10 M	
RST 8-282/...M	8	PUR, halogen-free	2 M / 5 M / 10 M	
RST 8-344/...M		PUR, halogen-free	10 M	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[RST 5-56/2 M](#) [RST 5-56/10 M](#) [RST 5-56/5 M](#)