

Mini Single-Ended Cordsets

RSW 30-838 | RSW 301-838

RSW 30-838



Description

MINI, Single-Ended Cordset, Right Angle, 3 Pole, 16 AWG, PLTC, Yellow. TPE Cable, U.S. Color Code, IP 67 and NEMA 6P Rated.

Technical Data


Material	
Molded body	TPU, yellow
Coupling nut	Aluminum, anodized black
Contacts	Brass, gold plated
Insert	TPE, yellow

Electrical	
Current rating	8 A
Voltage rating	600 V

Mechanical	
Temperature	-30°C to + 90°C
Protection	IP 67, NEMA 6P rated

Cable	
Jacket	PUR, Yellow
Gauge	16 AWG
UL	TC-ER
Outside diameter	.315"

RSW 30-838

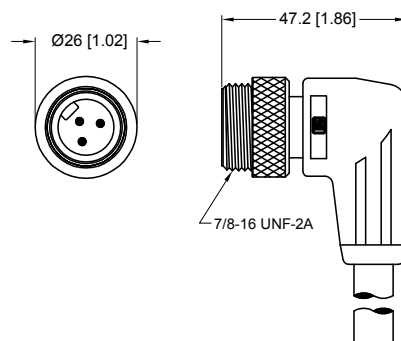


Part Number

RSW 30-838/1M
RSW 30-838/2M
RSW 30-838/3M
RSW 30-838/5M
RSW 30-838/10M
RSW 30-838/20M
RSW 301-838/1M
RSW 301-838/2M
RSW 301-838/3M
RSW 301-838/5M
RSW 301-838/10M
RSW 301-838/20M

RSW 301-838



RSW 301-838

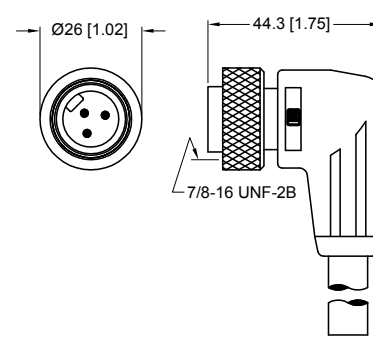

Pin Assignments

Face View 7/8"



- 1 = green
- 2 = black
- 3 = white



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[RSW 30-838/1M](#) [RSW 301-838/1M](#)