


Sound Level Meter with Backlit Display

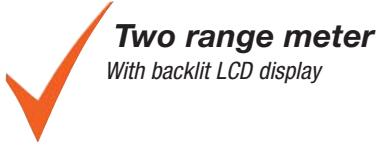

Two range meter
With backlit LCD display

Features:

- High accuracy meets ANSI and IEC 651 Type 2 standards
- High and Low measuring ranges
- Data Hold and Max Hold functions
- Backlit display to view in dimly lit area
- Complete with microphone wind screen and 9V battery

Applications:

- Enforcing community noise ordinances
- Meeting government safety issues (OSHA)
- Installing audio systems
- Product noise certification and reduction



Ordering Information:

407732.....Sound Level Meter with Backlit Display
407732-NISTSound Level Meter with Backlit Display with NIST

Specifications	
Display Counts	2000 count LCD
Range	Low: 35 to 100dB High: 65 to 130dB
Basic Accuracy	±1.5dB
Weighting (A & C)	Yes
Response Time (Fast/Slow)	Yes
Condenser Microphone	0.5" (12.7mm)
Dimensions	8.2x2.1x1.25" (210x55x32mm)
Weight	8.1oz (230g)



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Extech:](#)

[407732-NISTL](#) [407732](#)