


445713-TP Hygro-Thermometer with Remote Probe

Extech's Big Digit Hygro-Thermometer displays Indoor/ Outdoor Temperatures and Indoor Humidity reading simultaneously. The slender remote probe can be placed through small openings to take outdoor temperature from -58 to 158°F (-50 to 70°C). This can also be used to monitor temperature differences in two areas close to each other with probe cable length being 9.75ft (3m). Unit can be set on a desk top with built-in stand or hung on a wall.

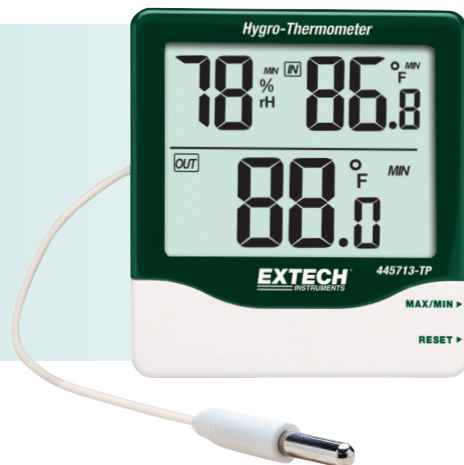

Features

- Temperature Ranges:
 - External Probe -58 to 158°F (-50 to 70°C)
 - Internal Sensor 32 to 122°F (0 to 50°C)
- Internal Relative Humidity Range: 20% to 99% RH
- Basic accuracy of $\pm 1.8^{\circ}\text{F}$ ($\pm 1.0^{\circ}\text{C}$), $\pm 5\%$ RH
- Max/Min with "reset" function
- Dimensions: 4.3 x 3.9 x 0.78" (109 x 99 x 20mm)
- Weight: 6oz (169g)
- Complete with built-in stand, wall mounting bracket, outdoor sensor with 9.75ft (3m) cable, and a 1.5V AAA battery

Ordering

445713-TP..... Hygro-Thermometer with Remote Probe



UPC Code: 793950457146

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Extech:](#)

[445713-TP](#)