


EMF/ELF Meter

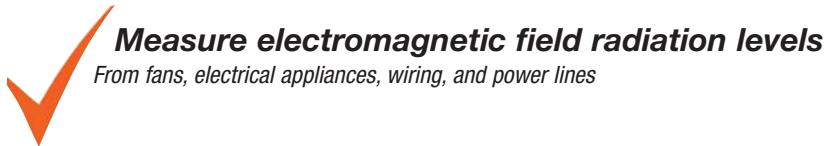

Features:

- Large 1/2" LCD (1999 count) display of Electromagnetic Field (EMF) level in milliGauss or microTesla
- Accurate measurements to 4% over a measuring range of 0.1 to 199.9mGauss (0.01 to 19.99 μ Tesla)
- ELF frequency bandwidth of 30 to 300Hz
Single axis - sampling 2.5 times per second
- CE approved, one year warranty
- Dims: 5.2x2.8x1"(132x71x25mm);
Weight: 6oz (170g)
- Complete with 9V battery



Specifications	
Range	0 to 199.9mG (milligauss) 0 to 19.99 μ Tesla
Frequency Bandwidth	30 to 300 Hz (ELF frequency range)
Accuracy	$\pm(4\% + 3\text{ digits})$ at 50-60 Hz
Number of Axes	Single axis

Ordering Information:

480823Electromagnetic Field Meter
409992Soft pouch carrying case



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Extech:](#)

[480823](#)