


ETK30 Electrical Test Kit with AC Clamp Meter



This special value Electrical Test Kit is assembled to provide all the electrical testing needs for installation and repair of electrical systems and HVAC equipment.

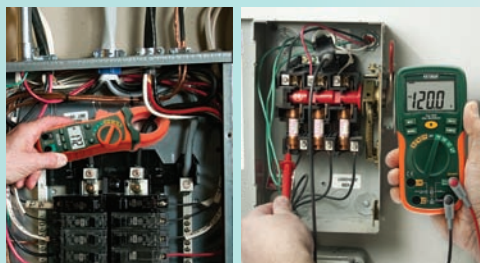

Kit Includes:

- EX205T True RMS Multimeter
- MA430 400A AC Clamp Meter with a built-in Non-Contact Voltage Detector with LED alert
- 1.2" (30mm) jaw size for conductors up to 350MCM
- Data Hold and Max Hold
- Exceptional Value Kit is supplied with test leads, batteries, and attractive storage case that provides protection and organization for the meters and accessories

Specifications	EX205T Range (Max Resolution)	MA430 Range (Max Resolution)
AC Voltage	600V (0.1mV) True RMS	600V (0.1mV)
DC Voltage	600V (0.1mV)	600V (0.1mV)
AC Current	10.00A (0.1μA) True RMS	400A (0.001A)
DC Current	10.00A (0.1μA)	—
Resistance	20MΩ (0.1Ω)	20MΩ (0.1Ω)
Continuity / Diode	Yes	Yes

Ordering

ETK30 Electrical Test Kit with AC Clamp Meter



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Extech:](#)

[ETK30](#)