
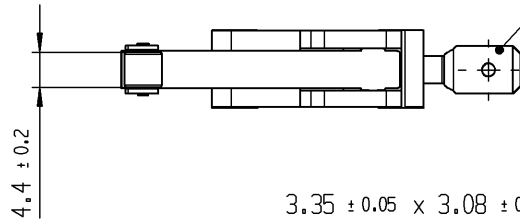


CONFIDENTIAL

VERTRAULICH



THIS DRAWING IS THE EXCLUSIVE PROPERTY OF MARQUARDT. WITHOUT THEIR CONSENT IT MAY NOT BE REPRODUCED OR GIVEN TO THIRD PARTIES.

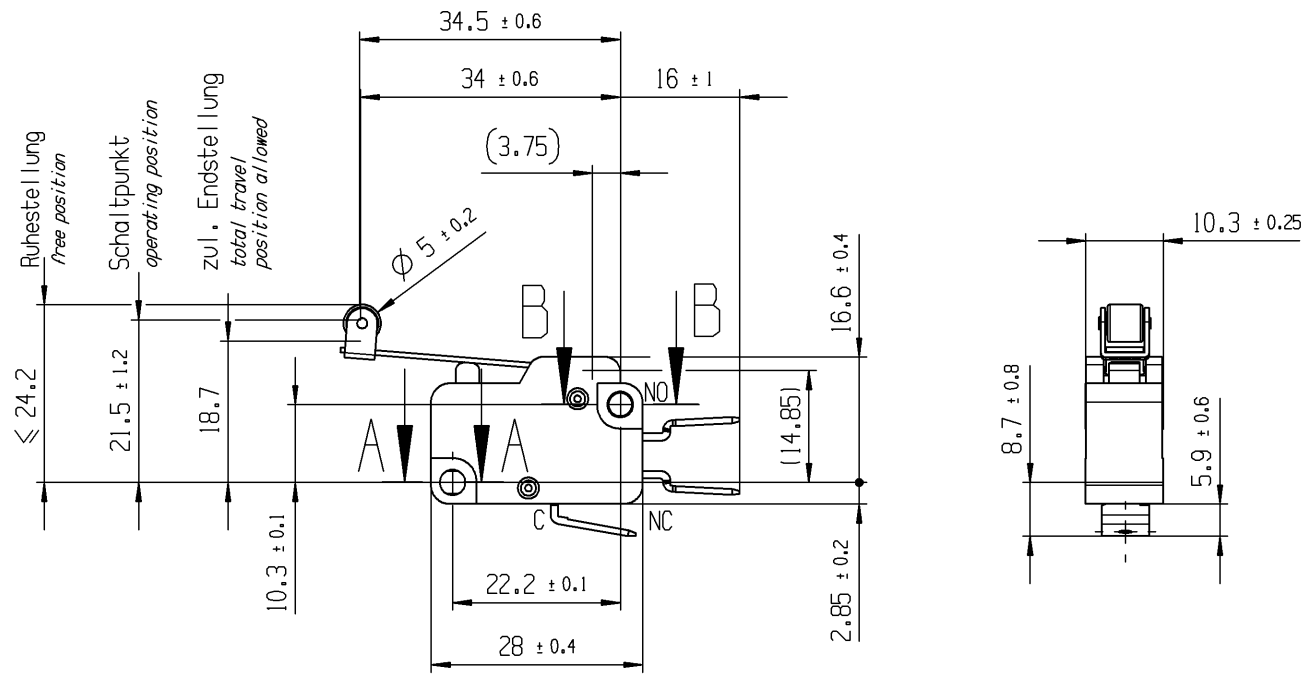

Flachstecker 6.3 x 0.8
EN 61058 / EN 61210 / DIN 46244
blade terminal 6.3 x 0.8
EN 61058 / EN 61210 / DIN 46244

A-A
2:1


B-B
2:1

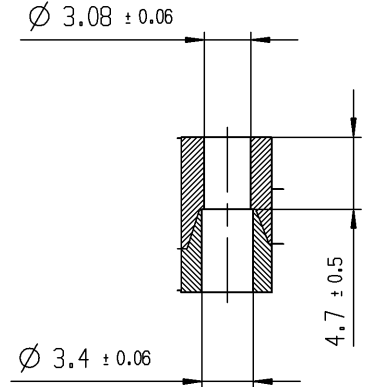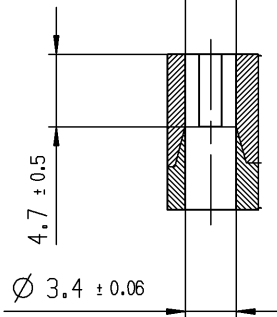


Aufschrift
marking



 1006 μ T100
10(14)A 400V AC 1E4
6(2.5)A 400V AC 5E4



Herstellort / -jahr / -woche
date code of manufacture:
place / year / week

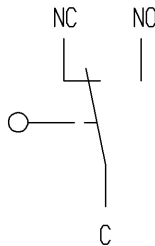

Wechsler 1-polig

single pole changeover

Schalt-Betaetigungskraft 0.7 bis 1.25 N
actuating force 0.7 up to 1.25 N

Differenzweg

movement differential

≤ 0.9 mm

Alle Rechte bei Marquardt, auch fuer den Fall von Schutzrechtsanmeldungen. Jede Veruegungsbefugnis, wie Kopier- und Weitergaberecht, bei uns.

-	-	-	1006.1501-XX							
Figure	Type	Customer No.	Art.No.-PI							
General tolerances										
All dimensions are in millimetres	Shape and location ⊙ ≡	Angle ± 2 °	Edge tolerance 	Length	Radii	Sheet 01	Ident. K	Document number 10061501	Index h	
				0-6	± 0.1					± 0.2
				>6-15	± 0.15					± 0.3
				>15-30	± 0.2					± 0.5
				>30-70	± 0.3					
				>70-120	± 0.4					± 10%
>120	± 0.8									
h	128297	2020-02-03	HHE	Format DIN A4	Projection	Scale 1:1	Snap action switch			
g	109072	2017-08-17	TRIGUIK							System NX V11.0
f	90078	2014-06-23	BRC							Replacement of Zg.gl.Nr.v.02.09.1999
e	87270	2014-01-10	BRC							
Index	MEC-No.	Date (YYYY-MM-DD)	Edited by							

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Marquardt:](#)

[1006.1501](#)