

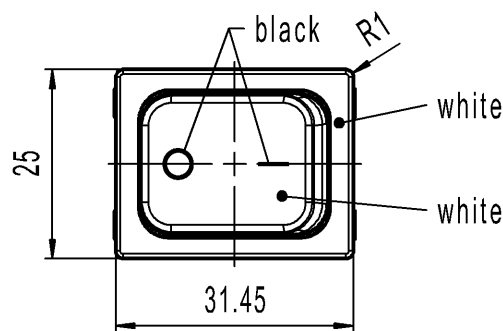


1	2	3	4
recommended cut-out for snap-in fixing (edge opposite to snap-in direction)	wall thickness	length of cut-out	width of cut-out
	0.75 to 1.25	30.0 -0.1	22 +0.2
	1.25 to 2	30.2 -0.1	22 +0.2
	2 to 3	30.6 -0.1	22 +0.2

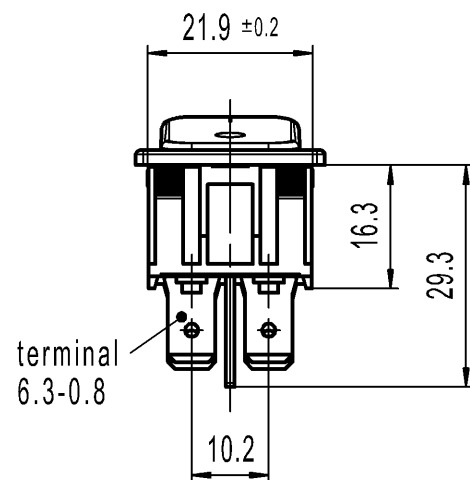

Marking:

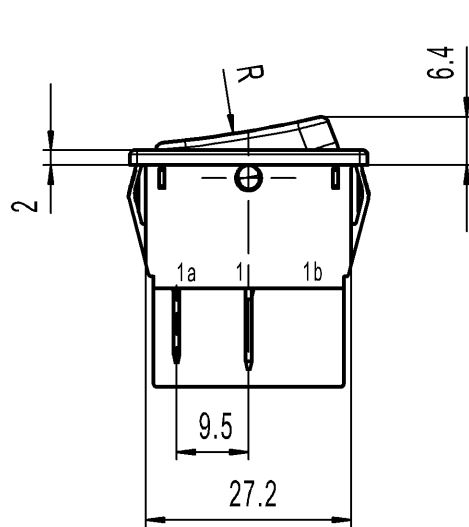

1832.
10(8)/250~5E4
20(4)/250~ T105/55
5/120A 250V~




16A 125-250V AC

1/3HP 125V AC


1HP 250V AC

R11

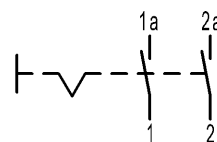

DPST

Suitable for appliances of class II

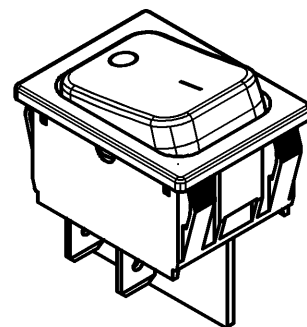

Code of manufacture: place/year/week

-	-	-	1832.3311-XX
Figure	Type	Customer Part No.	Art.No.-PI
Shape and location 	Angle ± 2 °	Sheet 01	
	Edge tolerance	Ident. K	Document number 18323311
		Index e	
		Appliance Switch	
e	138977	2021-10-19	MATHPATIR
d	64507	2009-11-11	HHE
c	39880	2004-03-15	HHE
b	24370	1996-10-31	GRH
Index	MEC-No.	Date (YYYY-MM-DD)	Edited by
All dimensions are in millimetres		System NX V1872	Replacement of Zg.gl.Nr.v.13.12.1991
		MARQUARDT	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Marquardt:](#)

[01832.3311-01](#)