


Flachstecker DIN 46 244-A2.8-0.5  
(EN 61058 / EN 61210)

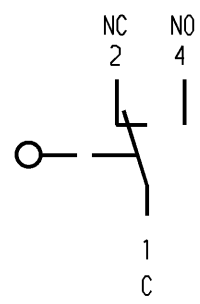

 
**Aufschrift**

Ⓜ  
1050 μ  
5/250~   
50E3 T100  
5A 125-250V AC 1/10HP  
R 56   
Herstelljahr/-woche  
nach DIN EN 60062

**Wechsler 1-polig**

Schalt-Betätigungskraft ≤ 1.50 N  
Rückschaltkraft ≥ 0.50 N  
Differenzweg ≤ 0.20 mm

Schutzvermerk nach DIN 34 beachten COPYRIGHT RESERVED

Allgemeintoleranzen/UNTOLERANCED DIMENSIONS				PROJECTION		Pause COPY		Blatt von SHEET OF		Zeichn./DRAWING NO.	
Für Längen und Radien FOR LENGTHS AND RADII.		Abmaße in mm für Nennmaßbereich in mm ALL DIMENSIONS ARE IN MILLIMETRES					Original DIN A4 Maßstab SCALE 2:1		5 1050.1202		
		bis/UP TO 6	über/OVER 6 bis/UP TO 30	über/OVER 30							
±		0.2	0.3			0 10 20 30 mm					
d				i		gez./DRAWN BY 16.10.91 Ble		Schnappschalter			
c				h		Ersatz für/REPLACEMENT OF					
b	29551	21.06.00	pfu	g				<b>MARQUARDT</b> Marquardt GmbH, D-78604 Riethim-Weilheim			
a	22621	19.01.94	mk	f							
				e							
Ausg. ISSUE	Änderung REVISION	gez. DRAWN BY		Ausg. ISSUE	Änderung REVISION	gez. DRAWN BY					

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Marquardt:](#)

[1050.1202](#)