

MODEL TL-2100



International size reference: AA, ER14505

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)



■ Nominal capacity @ 2 mA, to 2V	2.1 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	120 mA
■ Maximum pulse current capability	200 mA
■ Weight	17.6g (0.62 oz)
■ Volume	8 cc
■ Operating temperature range	-55°C to +85°C
■ U.L. Component Recognition, MH 12193	

***TADIRAN
LITHIUM
BATTERIES***

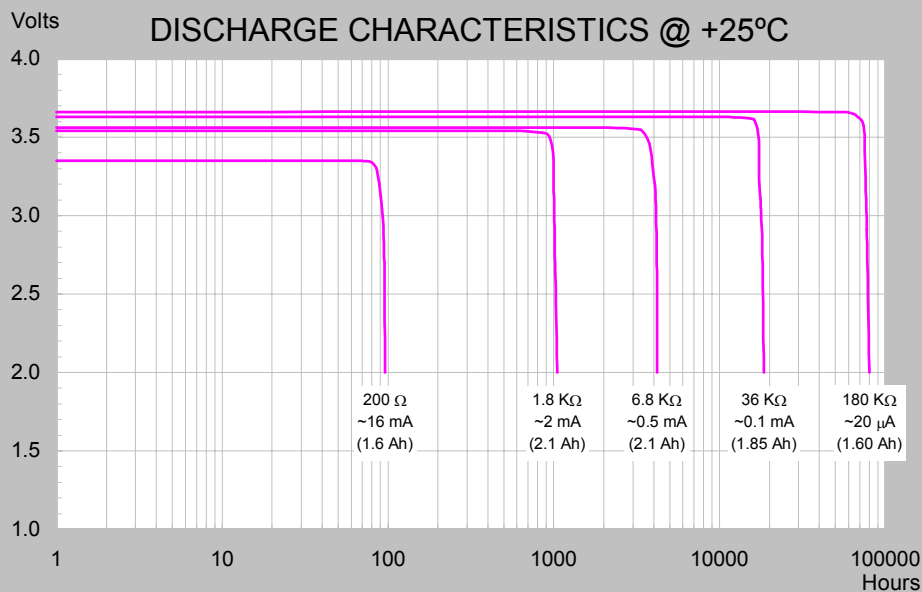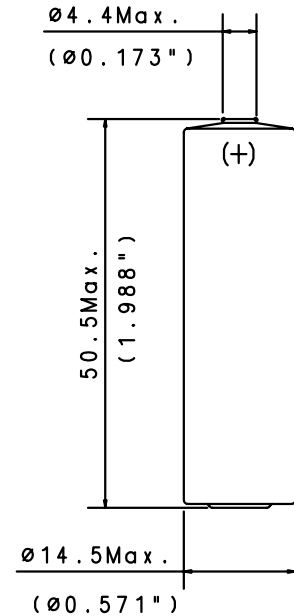

AVAILABLE TERMINATIONS

SUFFIX- /S STANDARD	15-5103-21500
SUFFIX- /T SOLDER TABS	15-5103-31500
SUFFIX- /P AXIAL PINS	15-5103-41500
SUFFIX- /PT2 RADIAL PINS	15-5103-36500
SUFFIX- /TP POLARIZED TABS	15-5103-52500
SUFFIX- /PT POLARIZED TABS	15-5103-53500

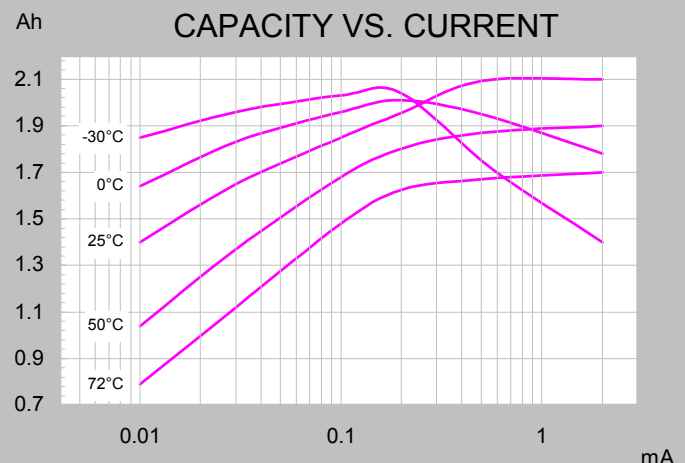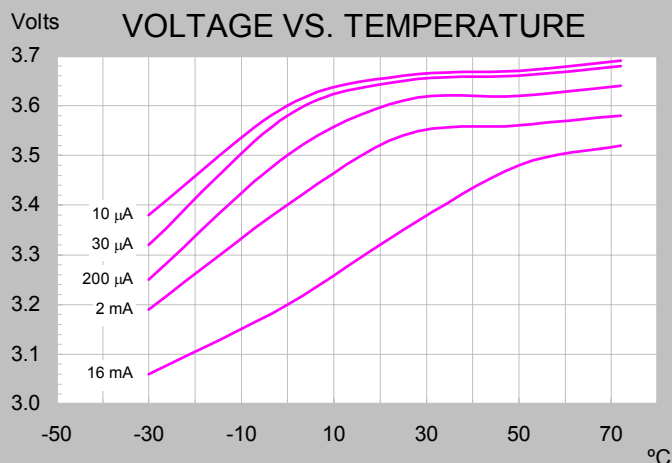

LITHIUM XTRA

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance.

Rev. B 04/03

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tadiran Batteries:](#)

[TL-2100/SBP](#) [TL-2100/PBP](#)