

MODEL TL-2150


International size reference: 1/2AA, ER14252

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)



■ Nominal capacity @ 1 mA, to 2V	1.0 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	50 mA
■ Maximum pulse current capability	100 mA
■ Weight	9.2g (0.324 oz)
■ Volume	4.3 cc
■ Operating temperature range	-55°C to +85°C
■ U.L. Component Recognition, MH 12193	

TADIRAN LITHIUM BATTERIES

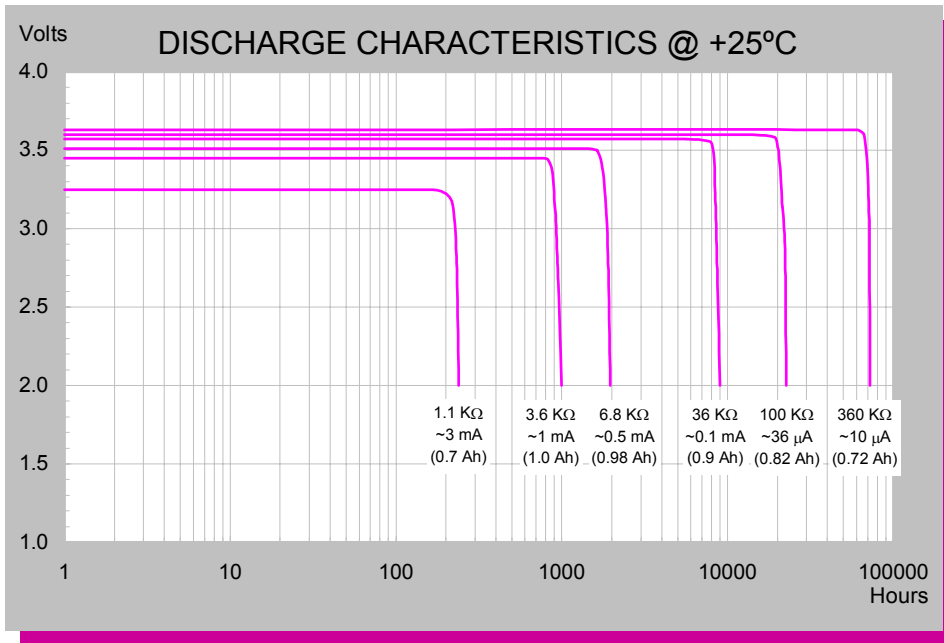

AVAILABLE TERMINATIONS

SUFFIX- /S STANDARD	15-5102-51020
SUFFIX- /T SOLDER TABS	15-5102-31500
SUFFIX- /P AXIAL PINS	15-5102-41500
SUFFIX- /PT2 RADIAL PINS	15-5102-36500
SUFFIX- /TP POLARIZED TABS	15-5102-52500
SUFFIX- /PT POLARIZED TABS	15-5102-53500

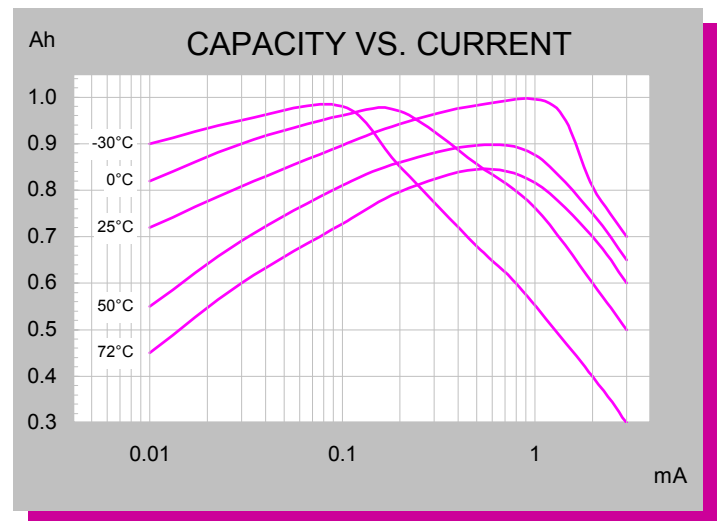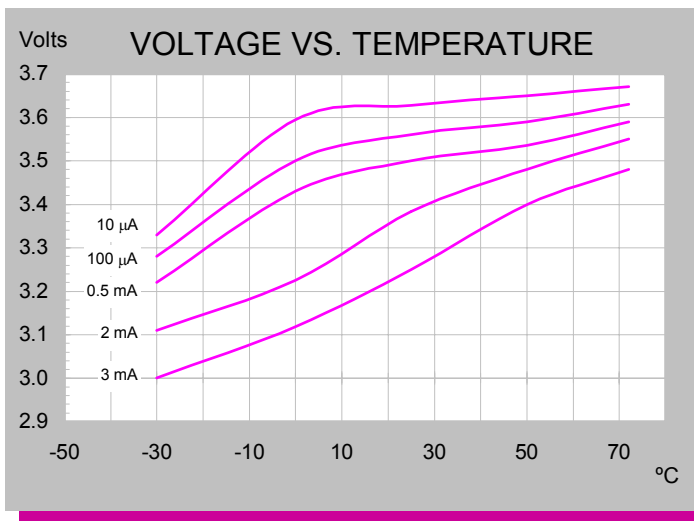

LITHIUM XTRA

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance. Rev. C 07/03

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Tadiran Batteries:

[TL2150/PT2](#) [TL2150/S](#) [TL2150/T](#) [TL2150/P](#) [TL2150/PT](#) [TL2150/TP](#)