

MODEL TL-2155



International size reference: 2/3AA, ER14335

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)



■ Nominal capacity @ 0.5 mA, to 2V	1.45 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	75 mA
■ Maximum pulse current capability	150 mA
■ Weight	12.4g (0.437 oz)
■ Volume	5.7 cc
■ Operating temperature range	-55°C to +85°C
■ U.L. Component Recognition, MH 12193	

TADIRAN
LITHIUM
BATTERIES

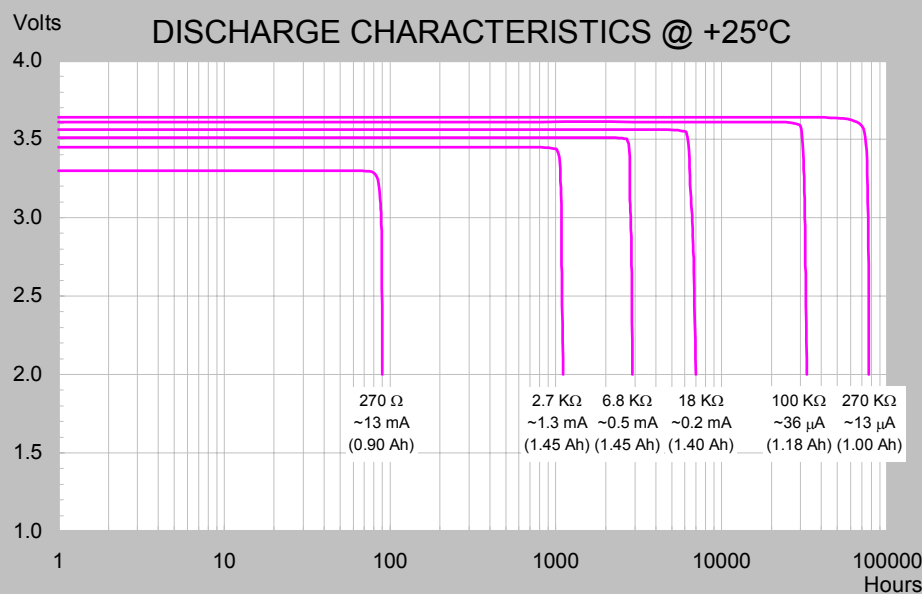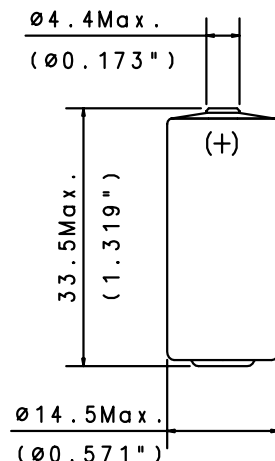

AVAILABLE TERMINATIONS

SUFFIX- /S STANDARD	15-5155-21500
SUFFIX- /T SOLDER TABS	15-5155-31500
SUFFIX- /P AXIAL PINS	15-5155-41500
SUFFIX- /PT2 RADIAL PINS	15-5155-36500
SUFFIX- /TP POLARIZED TABS	15-5155-52500
SUFFIX- /PT POLARIZED TABS	15-5155-53500

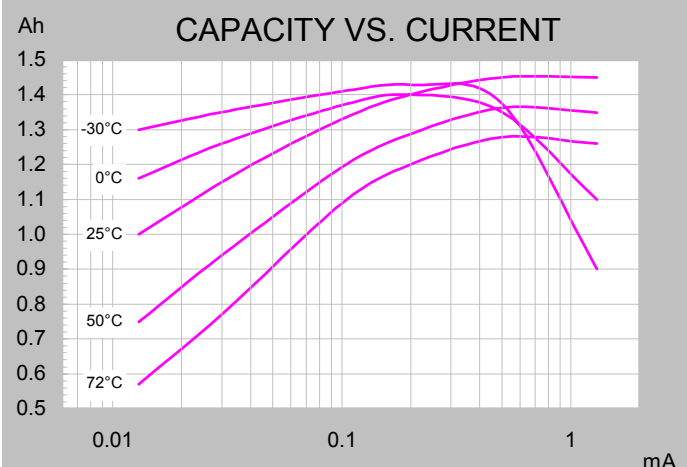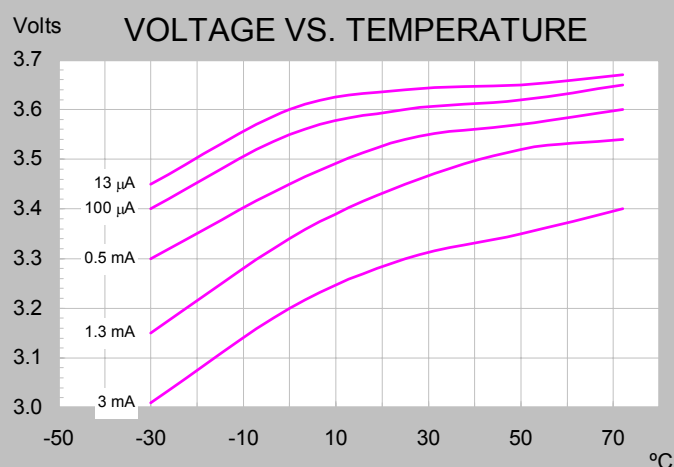

LITHIUM XTRA

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance.

Rev. B 04/03

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tadiran Batteries:](#)

[TL2155/P](#) [TL2155/S](#) [TL2155/T](#) [TL2155/TP](#) [TL2155/PT](#)