

MODEL TL-4903



International size reference: AA, ER14505

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)



■ Nominal capacity @ 1 mA, to 2 V	2.4 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	60 mA
■ Maximum 1 sec. pulse capability	120 mA
■ Weight	18 g (0.634 oz)
■ Volume	8 cc
■ Operating temperature range	-55 °C to +85 °C
■ U.L. Component Recognition, MH 12193	

***TADIRAN
LITHIUM
BATTERIES***

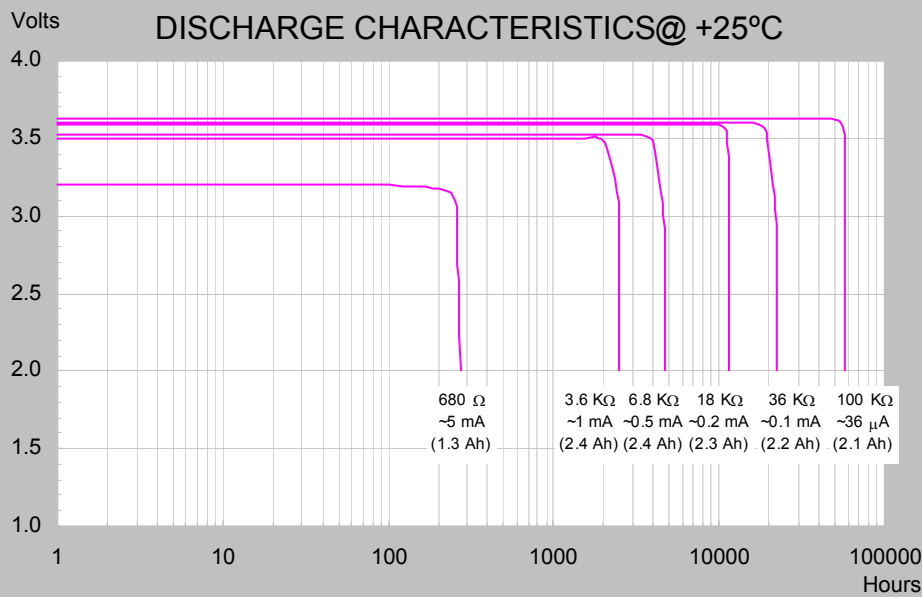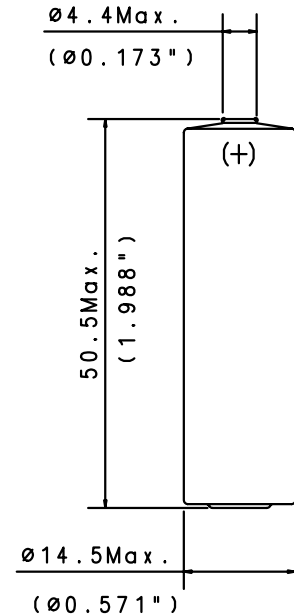

AVAILABLE TERMINATIONS

SUFFIX- /S STANDARD	15-4903-21000
SUFFIX- /T SOLDER TABS	15-4903-31000
SUFFIX- /P AXIAL PINS	15-4903-41000
SUFFIX- /PT2 RADIAL PINS	15-4903-36000
SUFFIX- /TP POLARIZED TABS	15-4903-52000
SUFFIX- /PT POLARIZED TABS	15-4903-53000

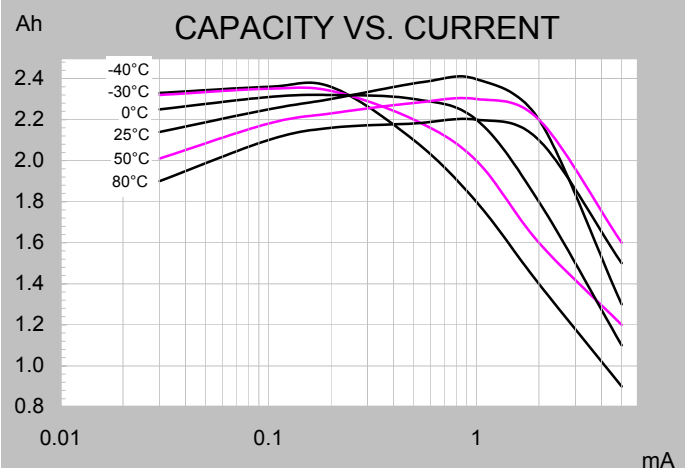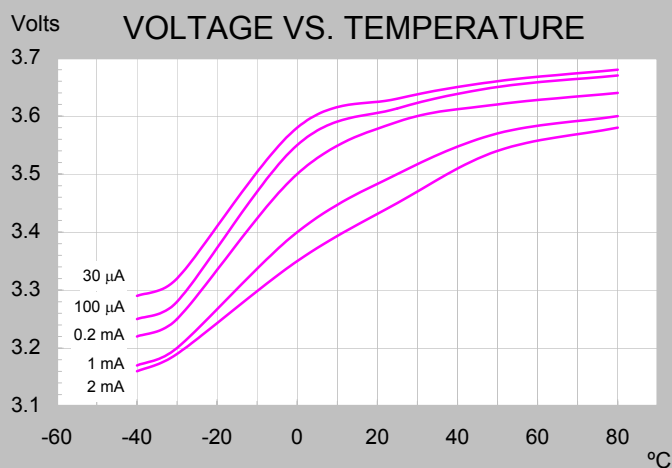

XOL - Extended Operating Life

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance.

Rev. D 01/07 ECN1501458

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Tadiran Batteries:

[TL4903S](#) [TL-4903/SBP](#) [TL-4903/P](#)