

MODEL TLH-5902



International size reference: 1/2AA, ER14252

TECHNICAL DATA

(Typical values @+25 °C for batteries stored for one year or less)



■ Nominal capacity @ 1 mA, to 2V	0.9 Ah
■ Rated voltage	3.6 V
■ Maximum recommended continuous current	50 mA
■ Maximum pulse current capability	100 mA
■ Weight	9.6 g (0.339 oz)
■ Volume	4 cc
■ Operating temperature range	-55 °C to +125 °C
■ Li metal content	approx. 0.35 g
■ U.L. Component Recognition, MH 12193	

***TADIRAN
LITHIUM
BATTERIES***

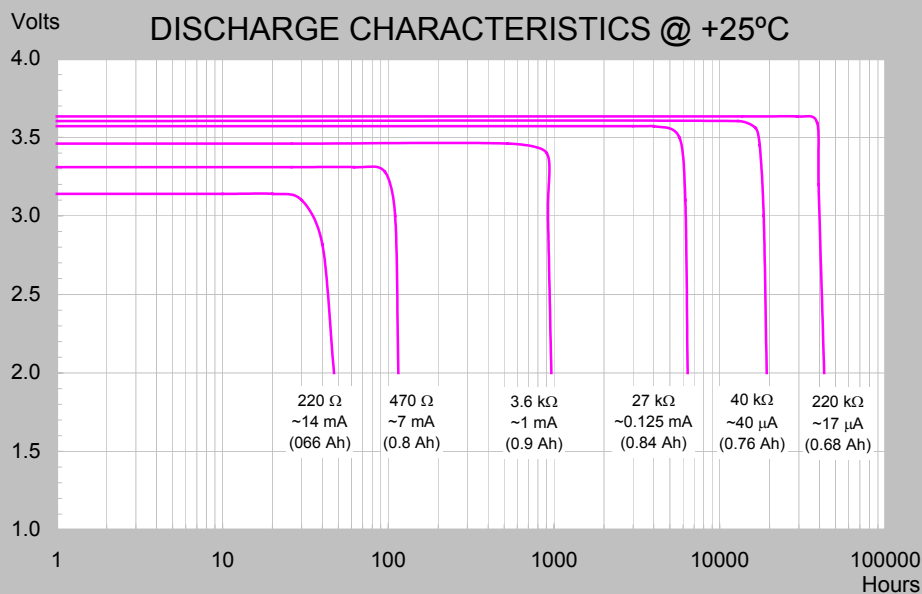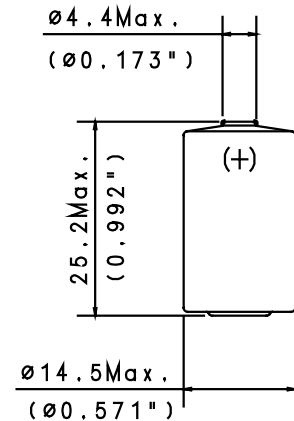

TERMINATIONS & ORDERING NO.

SUFFIX- /S STANDARD	15-5902-21505
SUFFIX- /T SOLDER TABS	15-5902-31505
SUFFIX- /P AXIAL PINS	15-5902-41505
SUFFIX- /PT2 RADIAL PINS	15-5902-36505
SUFFIX- /TP POLARIZED TABS	15-5902-52505
SUFFIX- /PT POLARIZED TABS	15-5902-53505

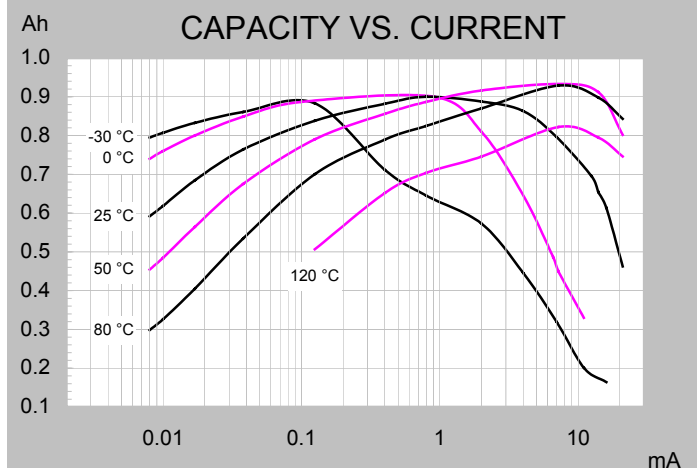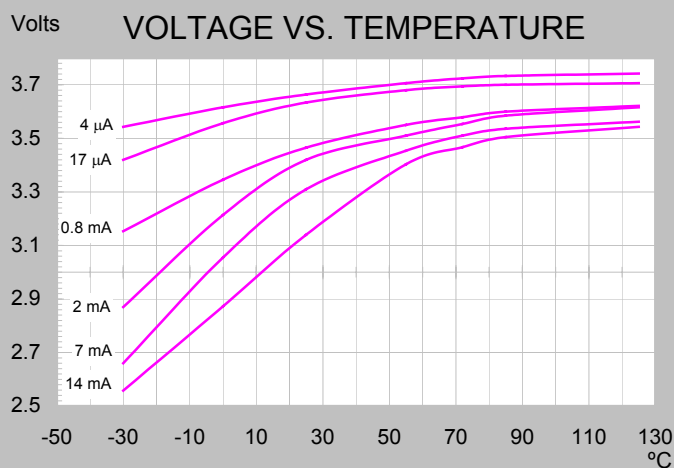

Extended Temperature Range

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance.

ECN 1501182 Rev. A 01/06

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Tadiran Batteries:

[TLH-5902/P](#) [TLH-5902/PT](#) [TLH-5902/S](#) [TLH-5902/T](#) [TLH-5902/TP](#) [TLH-5902/PBP](#) [TLH-5902/SBP](#) [TLH-5902/TBP](#)