



Assembly Hardware

Extruded, Self-Retaining LED

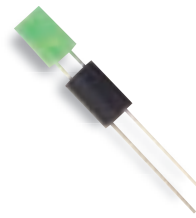

- For Use with All Rectangular LEDs
- Compatible with 2 & 3 Leaded Devices
- High Temperature version available by special order.
- See page 41 for ordering information.

ERM Extruded, Self-Retaining LED Mounts

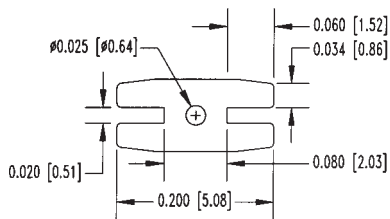

Material Specifications:

Black PVC U.L. Rated 94V-0 materials.



Oxygen Rating Index: Over 28%

Standard Tolerances Extruded LED Mounts

Tolerances: O.D. $\pm .005$ (.13), I.D. $\pm .005$ (.13)

"L" Dim: .030 - .500 (0.76 -12.7) is $\pm .005$ (.13)

"L" Dim: .505 - .750 (12.8-19.1) is $\pm .008$ (.20)

"L" Dim: .750 - 1.250 (19.2-21.8) is $\pm .015$ (.38)

ERB Extruded, Self-Retaining LED Mounts





- Standard Lengths from .030" - 1.250" (2.3 - 23.0 mm) in .005" (.127mm) increments
- Designed to mount T-1 (3mm) & T-1 $\frac{3}{4}$ (5mm) LEDs in a vertical or right angle position.

PART NO.	LED TYPE	LEAD NO.	'L'
ERB-XXX	All types	2 OR 3	.030-.900 (0.76-23.0)

Example: ERB-250 "L" Dimension of 0.250"

Note: High temperature versions available upon request.
Minor mechanical differences may exist.

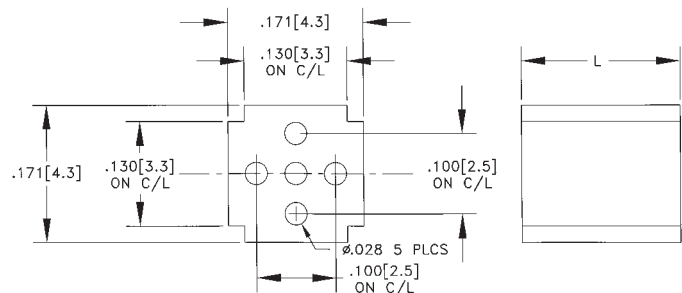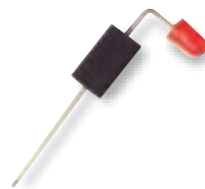

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[ERB-560](#) [ERB-030](#) [ERB-040](#) [ERB-050](#) [ERB-055](#) [ERB-060](#) [ERB-075](#) [ERB-080](#) [ERB-090](#) [ERB-095](#) [ERB-1.000](#)
[ERB-1.030](#) [ERB-100](#) [ERB-105](#) [ERB-10MM](#) [ERB-110](#) [ERB-11MM](#) [ERB-120](#) [ERB-125](#) [ERB-12MM](#) [ERB-130](#) [ERB-](#)
[13MM](#) [ERB-140](#) [ERB-145](#) [ERB-150](#) [ERB-155](#) [ERB-15MM](#) [ERB-160](#) [ERB-165](#) [ERB-16MM](#) [ERB-170](#) [ERB-175](#)
[ERB-180](#) [ERB-18MM](#) [ERB-190](#) [ERB-195](#) [ERB-200](#) [ERB-20MM](#) [ERB-210](#) [ERB-215](#) [ERB-220](#) [ERB-225](#) [ERB-](#)
[22MM](#) [ERB-230](#) [ERB-235](#) [ERB-240](#) [ERB-245](#) [ERB-24MM](#) [ERB-250](#) [ERB-260](#) [ERB-270](#) [ERB-275](#) [ERB-280](#)
[ERB-290](#) [ERB-295](#) [ERB-2MM](#) [ERB-300](#) [ERB-310](#) [ERB-315](#) [ERB-320](#) [ERB-325](#) [ERB-335](#) [ERB-340](#) [ERB-350](#)
[ERB-365](#) [ERB-370](#) [ERB-375](#) [ERB-380](#) [ERB-385](#) [ERB-395](#) [ERB-3MM](#) [ERB-400](#) [ERB-405](#) [ERB-415](#) [ERB-425](#)
[ERB-430](#) [ERB-435](#) [ERB-440](#) [ERB-450](#) [ERB-460](#) [ERB-465](#) [ERB-470](#) [ERB-475](#) [ERB-495](#) [ERB-4MM](#) [ERB-500](#)
[ERB-510](#) [ERB-515](#) [ERB-525](#) [ERB-530](#) [ERB-535](#) [ERB-550](#) [ERB-570](#) [ERB-575](#) [ERB-580](#) [ERB-5MM](#) [ERB-600](#)
[ERB-610](#) [ERB-620](#) [ERB-625](#)