

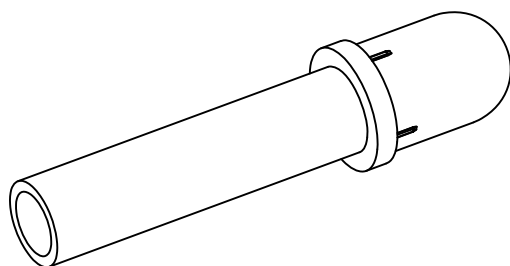


REV.	DESCRIPTION	DATE	APPROVED
E	Engineering Update w/o Changes	03/09/04	M. C.
F	Added Concave Entry Feature	08/26/09	T. Y.
G	Updated General Specifications Note 1.	10/01/12	T. Y.
H	Added Panel Thickness.	05/01/15	J. C.
J	Added Color Options, Sheet #2.	02/02/16	J. C.

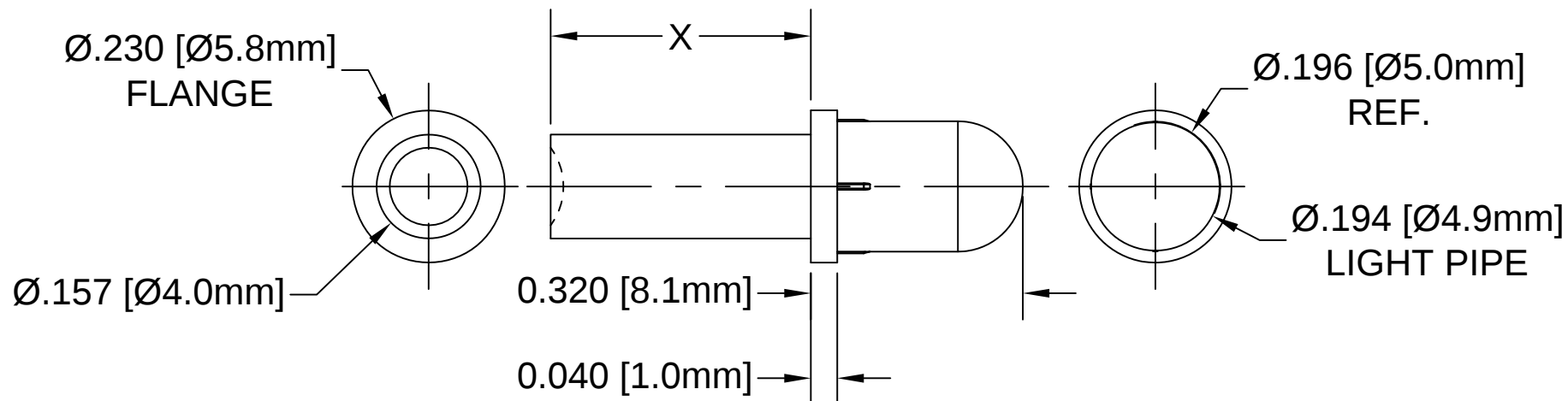

Part No.	X = Body Length
PLP5-125	0.125 (3.2mm)
PLP5-250	0.250 (6.4mm)
PLP5-350	0.350 (8.9mm)
PLP5-375	0.375 (9.5mm)
PLP5-500	0.500 (12.7mm)
PLP5-625	0.625 (15.9mm)
PLP5-750	0.750 (19.0mm)
PLP5-1000	1.000 (25.4mm)
PLP5-1250	1.250 (31.8mm)
PLP5-1500	1.500 (38.1mm)

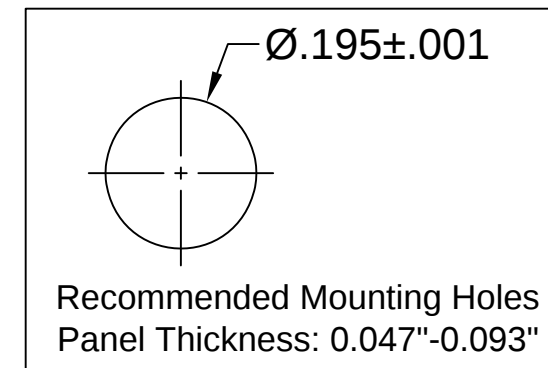


2. MATERIAL: POLYCARBONATE, 94V-0, CLEAR.

1. GENERAL SPECIFICATIONS: BIVAR MOLDED COMPONENT SPECIFICATION BV00-E101 and BSMC-1001.

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		 4 THOMAS, IRVINE, CA. 92618 TEL.: (949) 951-8808 FAX: (949) 951-3974	
DECIMALS	ANGULAR		
.X $\pm .1$	X° $\pm 1^\circ$		
.XX $\pm .02$			
.XXX $\pm .010$			
DESIGNED: Michael Chen	DATE: 01/14/03	 TITLE: LIGHT PIPE, PRESS-FIT PANEL MOUNT, ROUND TOP, 5mm	
CHECKED: D. Green	DATE: 01/14/03	PART NO: PLP5-XXX	REVISION: J
		CAGE CODE : 32559	SHEET # 1 OF 2
CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING.			

OTHER AVAILABLE COLORS
* SEE TABLE FOR ORDERING INFORMATION

REV.	DESCRIPTION	DATE	APPROVED
	SEE SHEET #1		

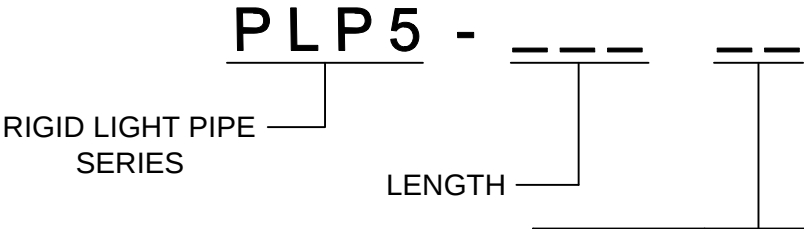

COLOR	Order Code
BLUE	BE
BLACK	BK
GREEN	GN
GRAY	GY
RED	RD
YELLOW	YW

NOTE: LEAVE ORDER CODE BLANK
IF NO COLOR IS DESIRED.

3. PARTS ARE DYED TO COLOR UPON REQUEST.

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED) DECIMALS ANGULAR		BIVAR® 4 THOMAS, IRVINE, CA. 92618 TEL.: (949) 951-8808 FAX: (949) 951-3974	
		 TITLE: LIGHT PIPE, PRESS-FIT PANEL MOUNT, ROUND TOP, 5mm	
DESIGNED: K. Aukshunas	DATE: 01/22/16	PART NO: PLP5-XXX	REVISION: J
CHECKED: J. Chiang	DATE: 01/22/16	CAGE CODE : 32559	SHEET # 2 OF 2
CAD GENERATED DOCUMENT. DO NOT MEASURE DRAWING.			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[PLP5-1000 GN](#) [PLP5-1000 RD](#) [PLP5-1000 YW](#) [PLP5-125 BE](#) [PLP5-125 GN](#) [PLP5-125 RD](#) [PLP5-1500 GN](#) [PLP5-1500 RD](#) [PLP5-1500 YW](#) [PLP5-250 BE](#) [PLP5-250 GN](#) [PLP5-250 RD](#) [PLP5-250 YW](#) [PLP5-350 BE](#) [PLP5-350 RD](#) [PLP5-375 BE](#) [PLP5-375 GN](#) [PLP5-375 RD](#) [PLP5-375 YW](#) [PLP5-500 BE](#) [PLP5-500 GN](#) [PLP5-500 RD](#) [PLP5-500 YW](#) [PLP5-625 GN](#) [PLP5-625 RD](#) [PLP5-750 GN](#)