
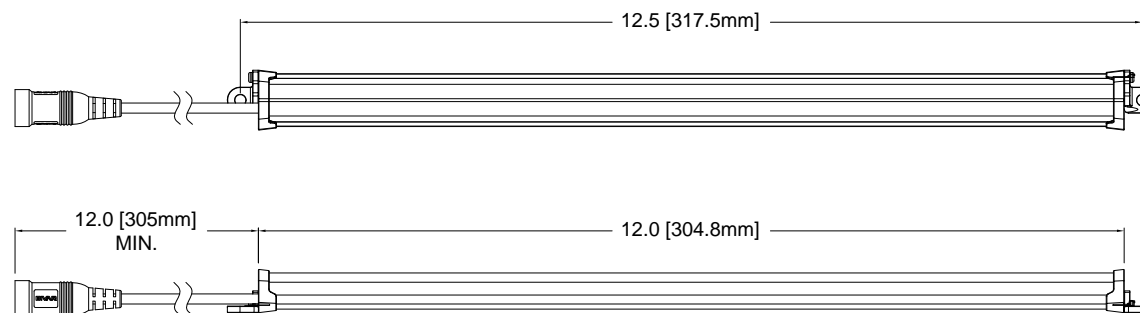
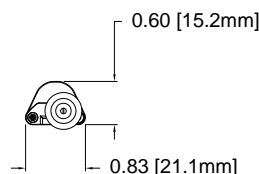


REV.	DESCRIPTION	DATE	APPROVED
A	Engineering Release	06/11/18	G.O.

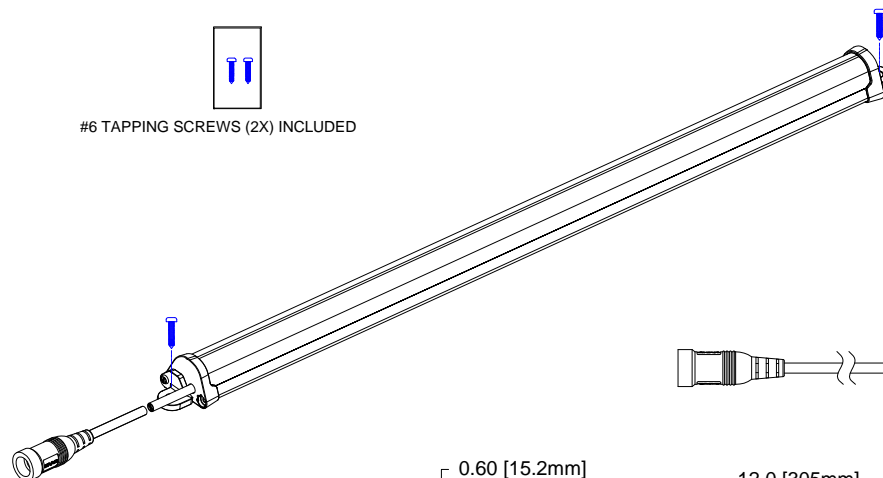

#6 TAPPING SCREWS (2X) INCLUDED


 


NOTES

1. Power Input: 24VDC, Constant Voltage
2. Power Consumption: 2.0 Watts
3. White Color Temperature: 4500K Neutral White
4. Output Projection: 120° FWHM
5. Luminous Output: 190 Lumens
6. Housing Color: Black
7. Operating Temperature: 0C ~ +40C
8. For Use in Dry Locations Only



Mating Connector:
5.5 x 2.1 x 11mm DC Plug

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		<div></div> 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
<u>DECIMALS</u>	<u>ANGULAR</u>	<div></div> TITLE: BP3100 SERIES LIGHT, SURFACE MOUNT, NEUTRAL WHITE	
.X ± .1	X° ± 1°		
.XX ± .02			
.XXX ± .010			
DESIGNED: K. BARON	DATE: 06/11/18	PART NO: BP3100-N-S	REVISION: A
REVISED: N/A	DATE: N/A	CAGE CODE: 32559	<div></div>
CHECKED: TD. NGUYEN	DATE: 06/11/18	SCALE: NONE	
CAD GENERATED DOCUMENT. DO NOT MEASURE DRAWING			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BIVAR:](#)

[BP3100-N-S](#)