

BIVAR

PM5-M124 SERIES

Smart Sensor Metal
Panel Mount Indicators

IP67 Rated



FEATURES AND BENEFITS




- IP67 rated and RoHS compliant.
- Smart sensor technology automatically senses and adjusts for appropriate intensity. Panel mount indicators are sunlight readable in bright lighting and auto dim in dark lighting.
- Wide viewing angle capabilities with a water clear Fresnel lens (7mm).
- Solid color indication in green, blue, red, and yellow.
- Black metal housing for ruggedized applications (shock and vibration resistant).
- Fast and easy installation with a panel thickness ranging from 0.040" - 0.250" and a standard mounting hole size of 0.315".
- Features non-polarized quick disconnect terminal blades which also work as soldering lugs for wire connection.
- Wide input range (12-24V) suitable for both AC and DC operation.

APPLICATIONS

- Servers and server appliances
- Test and measurement equipment
- Electrical and control instrument panels
- Military and utility vehicle dashboards
- Commercial and communication control boxes
- Wireless and power line infrastructure
- Water and waste treatment equipment

Part Number	Dominant Wave Length (nm)	Emitted Color	Lens Appearance	Voltage	Typical LED Intensity Iv(mcd) @ 0Lx	Viewing Angle
PM5-M124-BLU	465	Blue	Water Clear	12-24 VAC/VDC	20	100°
PM5-M124-GRN	530	Green	Water Clear	12-24 VAC/VDC	20	100°
PM5-M124-RED	625	Red	Water Clear	12-24 VAC/VDC	20	100°
PM5-M124-YLW	590	Yellow	Water Clear	12-24 VAC/VDC	20	100°

SPECIFICATIONS

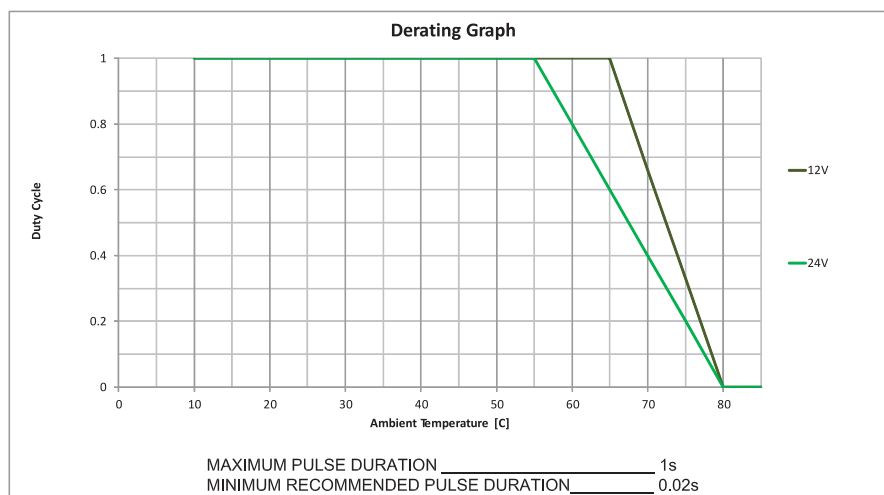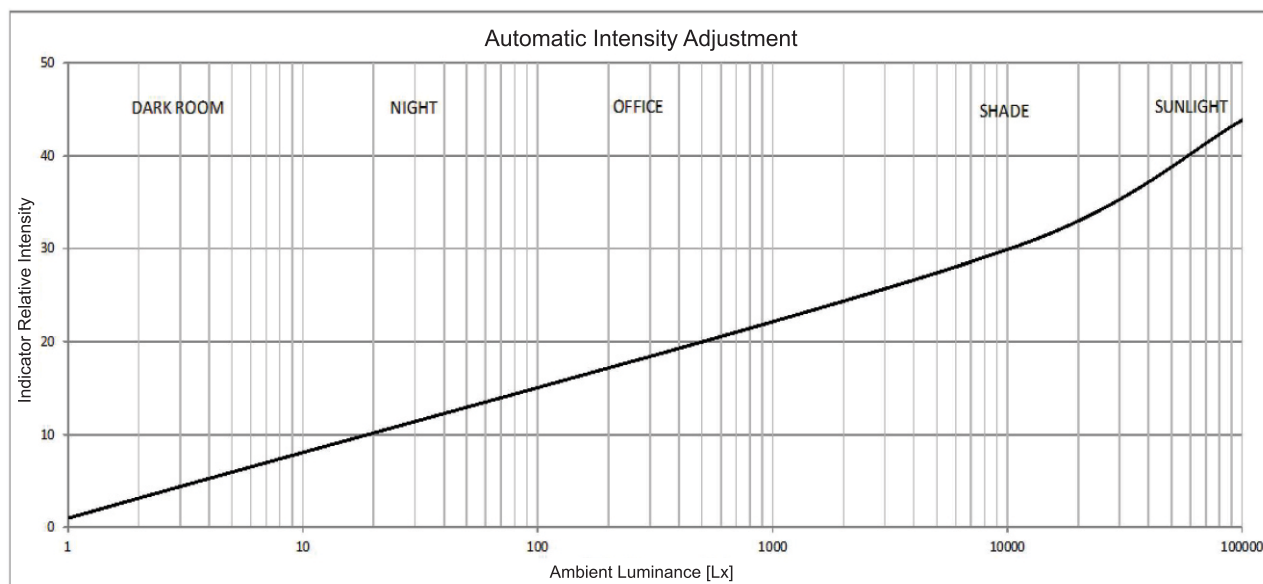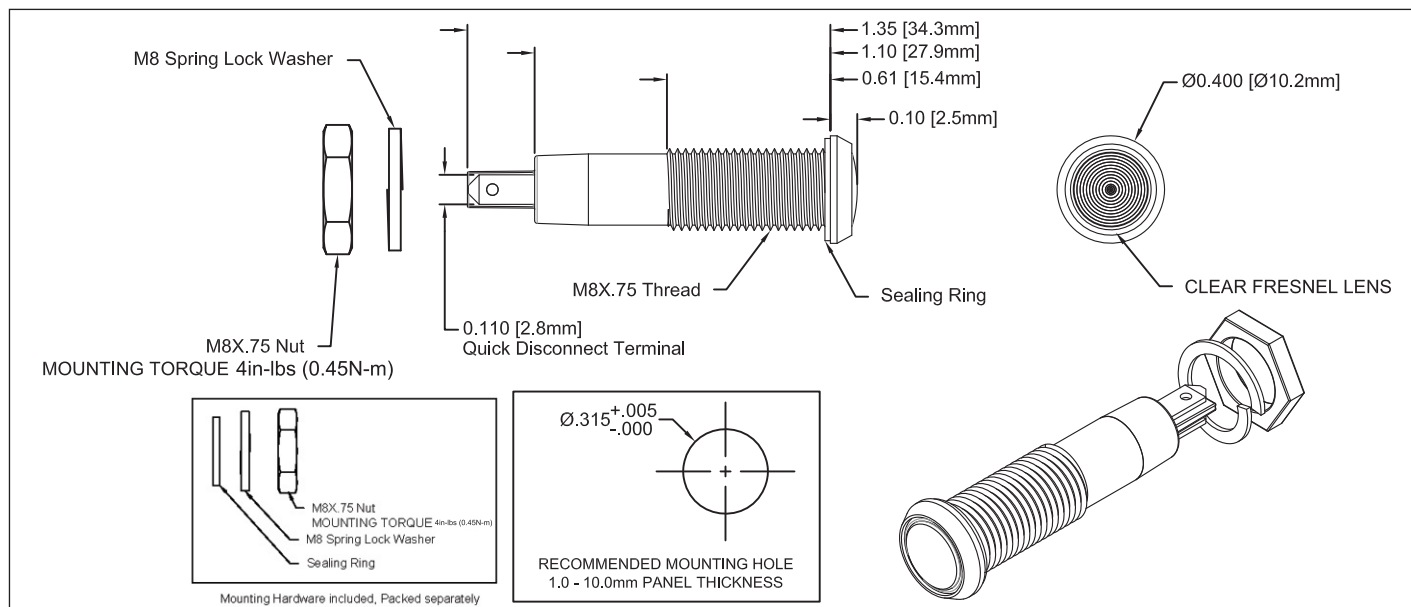

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[PM5-M124-BLU](#) [PM5-M124-GRN](#) [PM5-M124-RED](#) [PM5-M124-YLW](#)