

The Calafia Track Systems are easy to configure to fit your lighting needs. They are available in standard lengths and can easily utilize control and power accessories to increase the length, fit corners, and decoratively hide unsightly wires.

CLASS 2 POWER SUPPLY, 12WATT

CALIFIA LIGHTING PART #: PS-1032

SPECIFICATIONS


AC Input:	100-240 Vac 0.3A, 47-63Hz
DC Output:	24V / 500mA MAXIMUM 12 WATTS
Operating Temperature:	-30° C - 60° C
Peak Inrush:	10A @ 115V AC 20A @ 230V AC
Dimensions:	L 3.35" (85.1mm) W 1.35" (35mm) H .91" (23mm) 6" (152mm) stripped wires

Compliance:



Restriction of Hazardous Substances Directive (RoHS) implements EU Directive 2002 / 95 which bans placing electrical and hazardous equipment that contains more than agreed levels of hazardous substances on the EU market. For a list of these substances, visit www.rohs.gov.uk.

DIMENSIONS

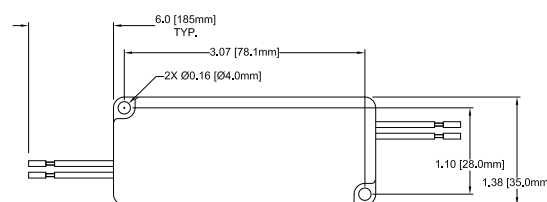

CLASS 2 POWER SUPPLY, 40WATT

CALIFIA LIGHTING PART #: PS-1033

SPECIFICATIONS


AC Input:	100-240 Vac 0.5A, 50-60Hz
DC Output:	24V / 1.67A MAXIMUM 40 WATTS
Operating Temperature:	-30° C - 70° C
Peak Inrush:	10A @ 115V AC 20A @ 230V AC
Dimensions:	L 3.74" (95mm) W 2.76" (70mm) H 1.26" (32mm) 6" (152mm) stripped wires

Compliance:



Restriction of Hazardous Substances Directive (RoHS) implements EU Directive 2002 / 95 which bans placing electrical and hazardous equipment that contains more than agreed levels of hazardous substances on the EU market. For a list of these substances, visit www.rohs.gov.uk.

DIMENSIONS

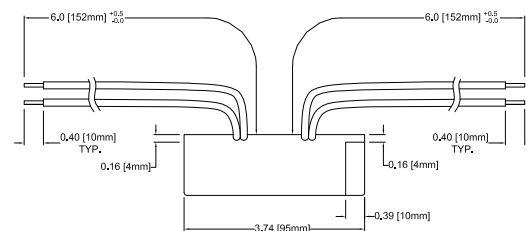

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Califia:](#)

[PS-1032](#) [PS-1033](#)