
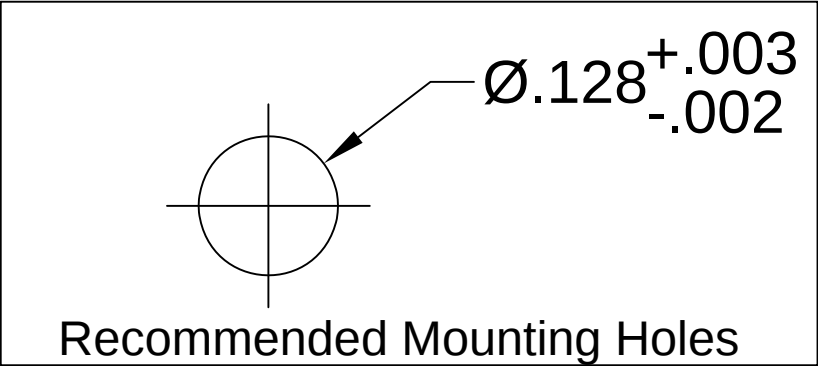


 
ITEM	Q'TY	PART NUMBER	PART DESCRIPTION
1	1	FLP-LC	HOLDER CAP, FLEXIBLE LIGHT-PIPE
2	1	FLPS1022-X.XXX	LIGHT PIPE CABLE, CUT LENGTH IN INCHES

REV.	DESCRIPTION	DATE	APPROVED
H	FLP Length Update	10/18/05	M. C.
J	FLP Length Clarification	01/11/06	M. C.
K	Corrected "L" Dimension Measurement	07/25/07	M. C.
M	Updated Fiber In BOM	11/14/12	T. Y.
N	Added Note 2	10/06/16	J. C.

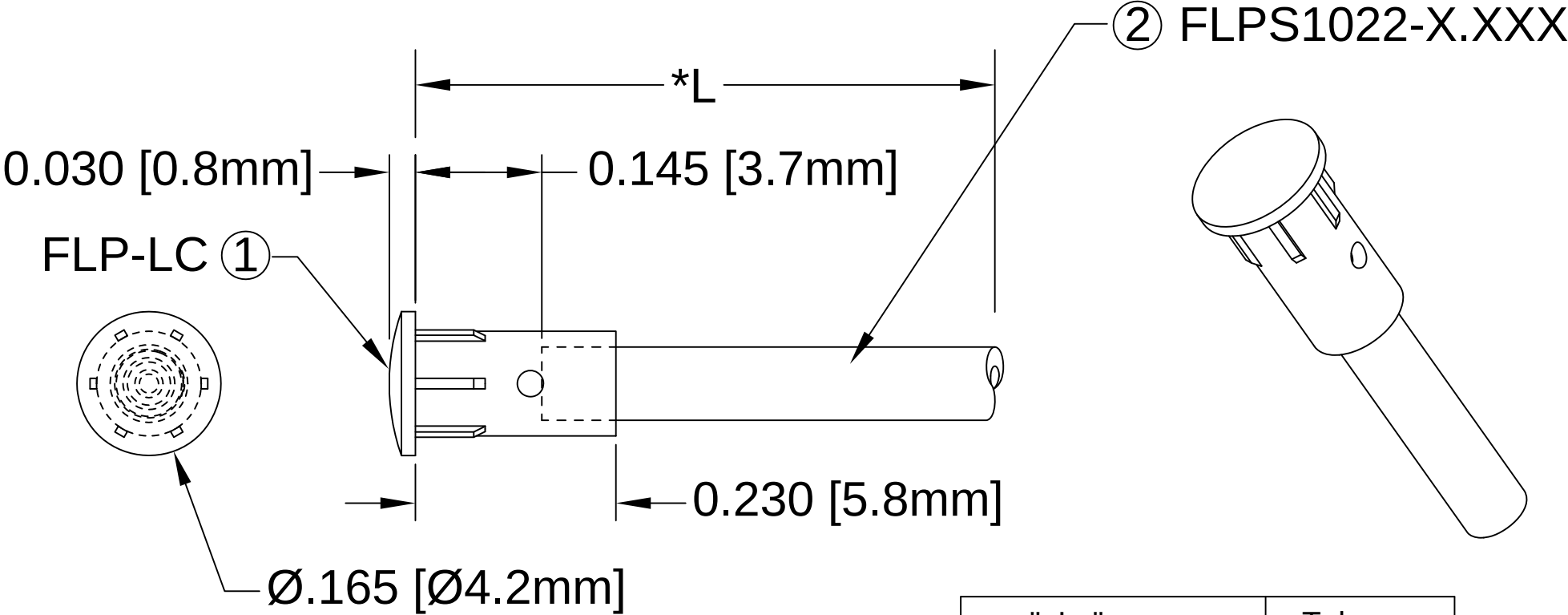

" L "	Tolerance
0.750" ~ 16.000"	±0.050"
16.100" ~ 40.000"	±0.150"
40.100" ~ 80.000"	±0.300"
80.100" ~ 3,940.0"	±0.5%

NOTE:
 1. ALLOWABLE CUT LENGTH IS UP TO 3 DECIMAL PLACES.
 2. MINIMUM BEND RADIUS OF FLEXIBLE LIGHT PIPE: 0.87" [22mm].

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		BIVAR® 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
<u>DECIMALS</u>	<u>ANGULAR</u>		
.X ± .1	X° ± 1°		
.XX ± .02			
.XXX ± .010		TITLE: LENS CAP / FLP ASSEMBLY, 4mm ROUND	
DESIGNED: S. Irving	DATE: 05/22/02	PART NO: LC-XX.X	REVISION: N
CHECKED: M. Chen	DATE: 05/22/02	CAGE CODE : 32559	SHEET # 1 OF 1
CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING.			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[LC-18.0](#) [LC-1.0](#) [LC-1.25](#) [LC-1.5](#) [LC-1.8](#) [LC-10.0](#) [LC-10.5](#) [LC-11.0](#) [LC-11.5](#) [LC-12.0](#) [LC-13.5](#) [LC-14.0](#) [LC-15.0](#)
[LC-15.5](#) [LC-16.0](#) [LC-18.4](#) [LC-2.0](#) [LC-2.25](#) [LC-2.5](#) [LC-2.75](#) [LC-20.0](#) [LC-21.0](#) [LC-24.0](#) [LC-27.0](#) [LC-3.0](#) [LC-3.1](#)
[LC-3.25](#) [LC-3.5](#) [LC-30.0](#) [LC-33.5](#) [LC-36.0](#) [LC-4.0](#) [LC-4.5](#) [LC-4.75](#) [LC-48.0](#) [LC-5.0](#) [LC-5.2](#) [LC-5.5](#) [LC-5.995](#) [LC-](#)
[6.0](#) [LC-6.29](#) [LC-6.5](#) [LC-6.6](#) [LC-6.75](#) [LC-60.0](#) [LC-7.0](#) [LC-7.1](#) [LC-7.5](#) [LC-7.7](#) [LC-7.75](#) [LC-7.85](#) [LC-7.9](#) [LC-72.0](#)
[LC-8.0](#) [LC-8.25](#) [LC-8.5](#) [LC-9.0](#) [LC-9.25](#) [LC-9.5](#) [LC-9.7](#) [LC-9.75](#) [LC-9.8](#) [LC-96.0](#) [LC-11.25](#) [LC-1.65](#) [LC-1.75](#) [LC-](#)
[11.8](#) [LC-2.285](#) [LC-20.5](#) [LC-14.25](#) [LC-6.25](#) [LC-16.5](#) [LC-21.5](#) [LC-22.0](#) [LC-20.25](#) [LC-4.25](#) [LC-6.8](#) [LC-76.0](#) [LC-](#)
[21.25](#) [LC-2.375](#) [LC-9.3](#) [LC-15.75](#) [LC-16.25](#) [LC-16.75](#) [LC-19.0](#) [LC-19.5](#) [LC-38.0](#) [LC-5.75](#) [LC-17.775](#) [LC-394.0](#)
[LC-5.88](#) [LC-40.0](#) [LC-13.0](#) [LC5-C](#) [LC-4.975](#) [LC-18.5](#) [LC-393.7](#)