


REV.	DESCRIPTION	DATE	APPROVED
D	Engineering Update w/o Changes	02/27/04	M. C.
E	Changed LTM Material from 44-BK to 56-BK	06/27/07	M. C.
F	Removed Material Code	05/21/16	J. C.

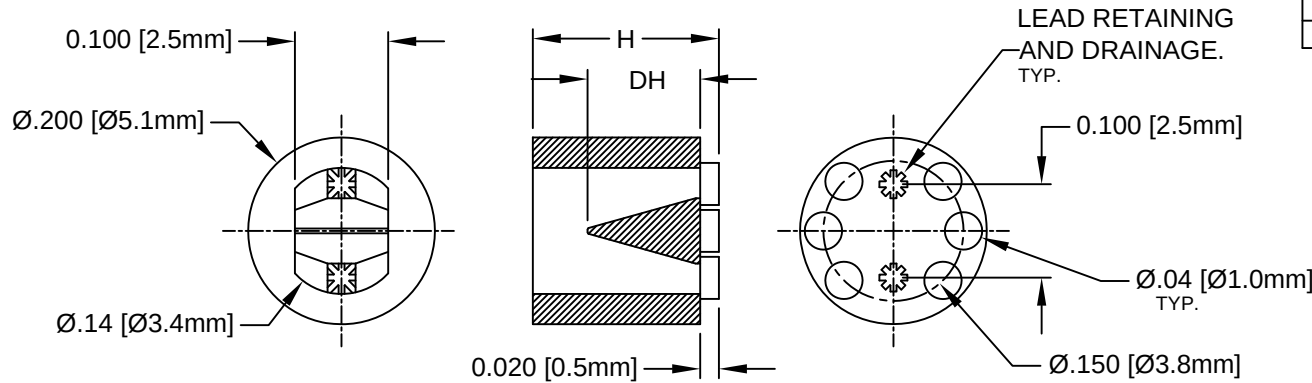

PART NO.	H	DH	PART NO.	H	DH	PART NO.	H	DH
LTM / NTM-120	.120(3.1)	.060(1.5)	LTM / NTM-300	.300(7.6)	.185(4.7)	LTM / NTM-490	.490(12.5)	.310(7.9)
LTM / NTM-130	.130(3.3)		LTM / NTM-310	.310(7.9)		LTM / NTM-500	.500(12.7)	.435(11.1)
LTM / NTM-140	.140(3.6)		LTM / NTM-320	.320(8.1)		LTM / NTM-520	.520(13.2)	
LTM / NTM-150	.150(3.8)		LTM / NTM-330	.330(8.4)		LTM / NTM-550	.550(14.0)	
LTM / NTM-160	.160(4.1)		LTM / NTM-340	.340(8.6)		LTM / NTM-570	.570(14.5)	
LTM / NTM-170	.170(4.3)		LTM / NTM-350	.350(8.9)		LTM / NTM-600	.600(15.2)	
LTM / NTM-180	.180(4.6)		LTM / NTM-360	.360(9.1)		LTM / NTM-620	.620(15.8)	.560(14.2)
LTM / NTM-190	.190(4.8)		LTM / NTM-370	.370(9.4)		LTM / NTM-650	.650(16.5)	
LTM / NTM-200	.200(5.1)		LTM / NTM-380	.380(9.7)		LTM / NTM-670	.670(17.0)	
LTM / NTM-210	.210(5.3)		LTM / NTM-390	.390(9.9)	.310(7.9)	LTM / NTM-700	.700(17.8)	.690(17.5)
LTM / NTM-220	.220(5.6)	.185(7.7)	LTM / NTM-400	.400(10.2)		LTM / NTM-720	.720(18.3)	
LTM / NTM-230	.230(5.8)		LTM / NTM-410	.410(10.4)		LTM / NTM-750	.750(19.1)	
LTM / NTM-240	.240(6.1)		LTM / NTM-420	.420(10.7)		LTM / NTM-770	.770(19.6)	
LTM / NTM-250	.250(6.4)		LTM / NTM-430	.430(10.9)		LTM / NTM-800	.800(20.3)	
LTM / NTM-260	.260(6.6)		LTM / NTM-440	.440(11.2)		LTM / NTM-820	.820(20.8)	
LTM / NTM-270	.270(6.9)		LTM / NTM-450	.450(11.4)		LTM / NTM-850	.850(21.6)	
LTM / NTM-280	.280(7.1)		LTM / NTM-460	.460(11.7)		LTM / NTM-870	.870(22.1)	
LTM / NTM-290	.290(7.4)		LTM / NTM-480	.480(12.2)		LTM / NTM-900	.900(22.9)	

3. NTM MATERIAL: NYLON 6/6, 94V-2, NATURAL.
2. LTM MATERIAL: MPPS, 94V-0, BLACK.
1. GENERAL SPECIFICATIONS: BIVAR MOLDED COMPONENT SPECIFICATION BV00-E101.

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
DECIMALS	ANGULAR		
.X ± .1	X° ± 1°		TITLE: MOLDED, SELF-RETAINING LED MOUNT
.XX ± .01			PART NO: LTM-NTM-XXX
.XXX ± .005		DESIGNED: D. Green	DATE: 01/06/03
		CHECKED: M. Chen	DATE: 01/06/03
			REVISION: F
			CAGE CODE : 32559 SHEET # 1 OF 1
			CAD GENERATED DOCUMENT. DO NOT MEASURE DRAWING.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[LTM-120](#) [LTM-150](#) [LTM-160](#) [LTM-200](#) [LTM-250](#) [LTM-300](#) [LTM-350](#) [LTM-400](#) [LTM-450](#) [LTM-500](#) [LTM-550](#)
[LTM-750](#) [LTM-460](#) [NTM-360](#) [LTM-370](#) [LTM-130](#) [LTM-140](#) [LTM-170](#) [LTM-180](#) [LTM-190](#) [LTM-210](#) [LTM-220](#) [LTM-230](#) [LTM-240](#) [LTM-260](#) [LTM-270](#) [LTM-280](#) [LTM-290](#) [LTM-310](#) [LTM-320](#) [LTM-330](#) [LTM-340](#) [LTM-360](#) [LTM-380](#)
[LTM-390](#) [LTM-410](#) [LTM-420](#) [LTM-430](#) [LTM-440](#) [LTM-480](#) [LTM-490](#) [LTM-520](#) [LTM-570](#) [LTM-600](#) [LTM-620](#) [LTM-650](#) [LTM-670](#) [LTM-700](#) [LTM-720](#) [LTM-770](#) [LTM-800](#) [LTM-820](#) [LTM-850](#) [LTM-870](#) [LTM-900](#) [NTM-120](#) [NTM-130](#)
[NTM-140](#) [NTM-150](#) [NTM-160](#) [NTM-170](#) [NTM-180](#) [NTM-190](#) [NTM-200](#) [NTM-210](#) [NTM-220](#) [NTM-230](#) [NTM-240](#) [NTM-250](#) [NTM-260](#) [NTM-270](#) [NTM-280](#) [NTM-290](#) [NTM-300](#) [NTM-310](#) [NTM-320](#) [NTM-330](#) [NTM-340](#) [NTM-350](#)
[NTM-370](#) [NTM-380](#) [NTM-390](#) [NTM-400](#) [NTM-410](#) [NTM-420](#) [NTM-430](#) [NTM-440](#) [NTM-450](#) [NTM-460](#) [NTM-480](#) [NTM-490](#) [NTM-500](#) [NTM-520](#) [NTM-530](#) [NTM-550](#) [NTM-570](#) [NTM-600](#) [NTM-620](#) [NTM-650](#) [NTM-670](#)