


# NOTES:

1. BEZEL MATERIAL IS NYLON 6/6, UL94 V-0
2. DOUBLE-SIDED ADHESIVE TAPE MATERIAL IS KRAFT PAPER WITH 3M 9482.
3. LIGHT PIPE IS CLEAR POLYCARBONATE, UL94 V-0.
4. ASSEMBLIES ARE PACKAGED AND SHIPPED ASSEMBLED.

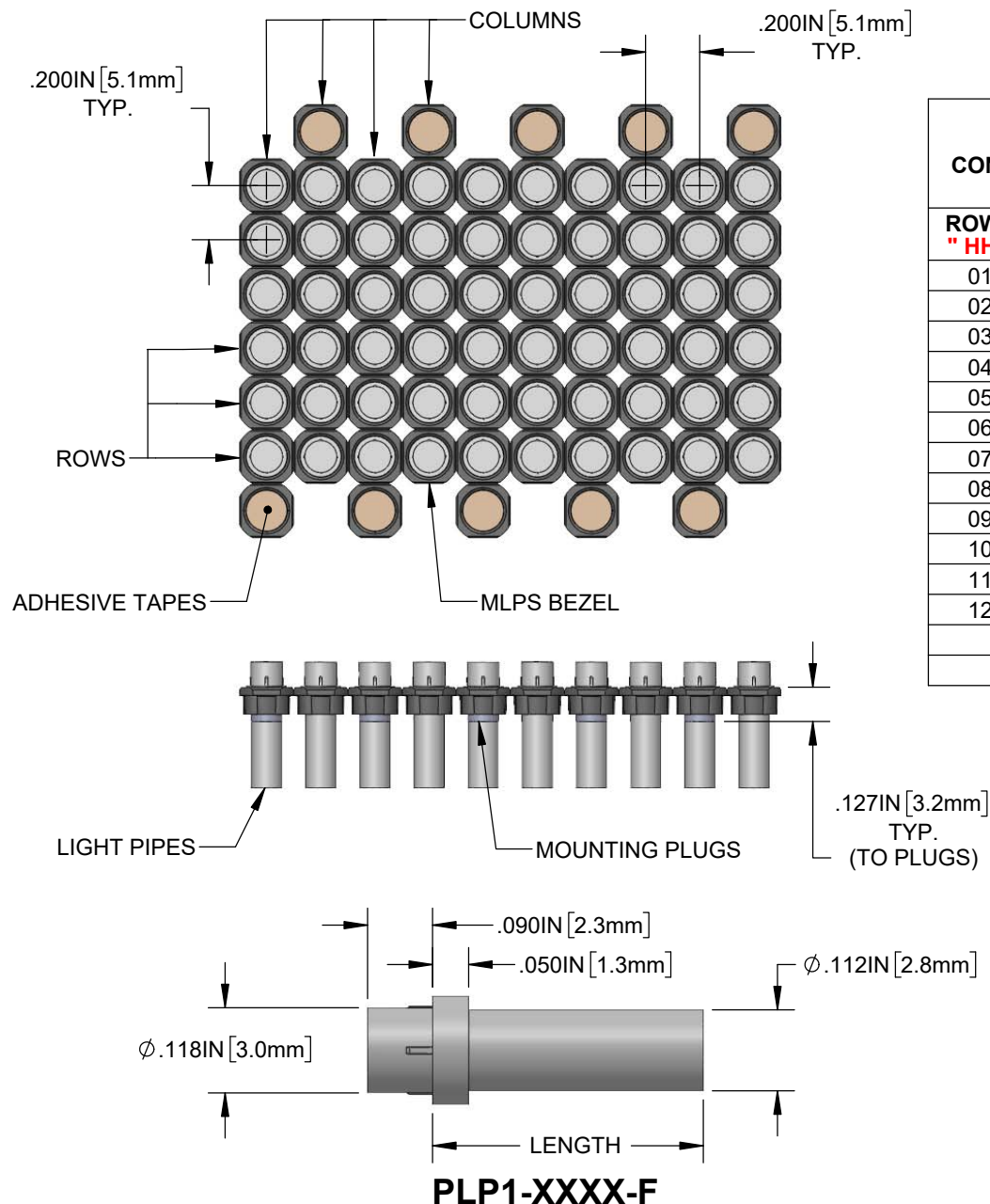

| REVISIONS |                     |          |          |
|-----------|---------------------|----------|----------|
| REV.      | DESCRIPTION         | DATE     | APPROVED |
| A         | ENGINEERING RELEASE | 07/19/23 | A.V.     |

PITCH (ROW-COLUMN)  
NO OF COLUMNS  
NO. OF ROWS  
BEZEL MOUNT  
LIGHT PIPE LENGTH

**P/N: MLPS - B - 3 - HHJJ - KK - T - PLP1-XXXX-F**

| ARRAY CONFIGURATION |                 | PITCH (ROW - COLUMN)<br>"KK" |             |                | BEZEL MOUNT<br>"T" | LIGHT PIPE LENGTH |                |
|---------------------|-----------------|------------------------------|-------------|----------------|--------------------|-------------------|----------------|
| ROWS<br>"HH"        | COLUMNS<br>"JJ" | PITCH                        | ROW<br>"K_" | COLUMN<br>"_K" |                    | LENGTH            | CODE<br>"XXXX" |
| 01                  | 01              | 0.000 IN<br>0.200 IN         | 0<br>C      | 0<br>C         | 2                  |                   |                |
| 02                  | 02              |                              |             |                | 4                  | .188 IN           | 188            |
| 03                  | 03              |                              |             |                | 6                  | .250 IN           | 250            |
| 04                  | 04              |                              |             |                | 8                  | .313 IN           | 313            |
| 05                  | 05              | 0.000 IN<br>0.200 IN         | 0<br>C      | 0<br>C         | 10                 | .350 IN           | 350            |
| 06                  | 06              |                              |             |                | 12                 | .375 IN           | 375            |
| 07                  | 07              |                              |             |                | 14                 | .500 IN           | 500            |
| 08                  | 08              |                              |             |                |                    | .625 IN           | 625            |
| 09                  | 09              | 0.000 IN<br>0.200 IN         | 0<br>C      | 0<br>C         |                    | .750 IN           | 750            |
| 10                  | 10              |                              |             |                |                    | .830 IN           | 830            |
| 11                  | 11              |                              |             |                |                    | 5.0 mm            | 5MM            |
| 12                  | 12              |                              |             |                |                    | 6.0 mm            | 6MM            |
|                     | 13              | 0.000 IN<br>0.200 IN         | 0<br>C      | 0<br>C         |                    | 7.0 mm            | 7MM            |
|                     | 14              |                              |             |                |                    | 8.0 mm            | 8MM            |
|                     |                 |                              |             |                |                    | 9.0 mm            | 9MM            |
|                     |                 |                              |             |                |                    | 10.0 mm           | 10MM           |

## PART NO. EXAMPLE:

**MLPS-B-3-0205-CC-2-PLP1-375-F**

2 ROWS, 5 COLUMNS  
.200 X .200 PITCH (ROW-COLUMN)  
2 BEZEL MOUNTS  
PLP1-375-F LIGHT PIPE

## CUSTOMER USE DRAWING

|                                                    |                     |                                                                            |  |
|----------------------------------------------------|---------------------|----------------------------------------------------------------------------|--|
| STANDARD TOLERANCE<br>(UNLESS OTHERWISE SPECIFIED) |                     | <br>4 THOMAS, IRVINE, CA. 92618<br>TEL: (949) 951-8808 FAX: (949) 951-3974 |  |
| DECIMALS                                           | ANGULAR             |                                                                            |  |
| .X ± .1                                            | X° ± 1°             | <br><b>TITLE:</b> MODULAR LIGHT PIPE<br>SYSTEM, BEZEL, PLP1-XXXX-F         |  |
| .XX ± .01                                          |                     |                                                                            |  |
| .XXX ± .005                                        |                     | <b>DRAWING NO:</b><br>MLPS-B-3-HHJJ-KK-T-PLP1-XXXX-F_A                     |  |
| DESIGNED:<br>A.VALDEZ                              | DATE:<br>07/19/2023 | <b>REVISION:</b><br>A                                                      |  |
| REvised:                                           | DATE:               | <b>SHEET SIZE</b><br>A                                                     |  |
| CHECKED:<br>MICHAEL P.                             | DATE:<br>07/19/2023 | <b>CAGE CODE:</b><br>32559                                                 |  |
|                                                    |                     | <b>SCALE:</b> N/A                                                          |  |
|                                                    |                     | <b>SHEET # 1 OF 1</b>                                                      |  |

CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BIVAR:](#)

[MLPS-B-3-1206-CC-10-PLP1-350-F](#) [MLPS-B-3-0206-CC-2-PLP1-350-F](#) [MLPS-B-3-0202-CC-2-PLP1-350-F](#) [MLPS-B-3-0106-C0-2-PLP1-350-F](#) [MLPS-B-3-0104-C0-2-PLP1-350-F](#) [MLPS-B-3-0304-CC-2-PLP1-350-F](#) [MLPS-B-3-0201-CC-2-PLP1-350-F](#) [MLPS-B-3-1206-CC-12-PLP1-350-F](#) [MLPS-B-3-0104-C0-2-PLP1-375-F](#) [MLPS-B-3-0105-C0-2-PLP1-500-F](#) [MLPS-B-3-0106-C0-2-PLP1-6MM-F](#) [MLPS-B-3-0106-C0-2-PLP1-750-F](#) [MLPS-B-3-0106-C0-2-PLP1-9MM-F](#) [MLPS-B-3-0107-C0-4-PLP1-250-F](#) [MLPS-B-3-0111-C0-4-PLP1-250-F](#) [MLPS-B-3-0112-C0-4-PLP1-250-F](#) [MLPS-B-3-0203-CC-2-PLP1-500-F](#) [MLPS-B-3-0206-CC-2-PLP1-250-F](#) [MLPS-B-3-0207-CC-4-PLP1-500-F](#) [MLPS-B-3-0303-CC-2-PLP1-7MM-F](#) [MLPS-B-3-0306-CC-4-PLP1-7MM-F](#) [MLPS-B-3-0307-CC-4-PLP1-7MM-F](#) [MLPS-B-3-0310-CC-4-PLP1-7MM-F](#) [MLPS-B-3-0311-CC-6-PLP1-7MM-F](#) [MLPS-B-3-0314-CC-10-PLP1-750-F](#) [MLPS-B-3-0401-CC-2-PLP1-8MM-F](#) [MLPS-B-3-0401-CC-2-PLP1-9MM-F](#) [MLPS-B-3-0402-CC-2-PLP1-188-F](#) [MLPS-B-3-0404-CC-4-PLP1-375-F](#) [MLPS-B-3-0405-CC-4-PLP1-625-F](#) [MLPS-B-3-0405-CC-4-PLP1-830-F](#) [MLPS-B-3-0406-CC-4-PLP1-10MM-F](#) [MLPS-B-3-0406-CC-4-PLP1-830-F](#) [MLPS-B-3-0406-CC-4-PLP1-8MM-F](#) [MLPS-B-3-0407-CC-4-PLP1-10MM-F](#) [MLPS-B-3-0407-CC-4-PLP1-350-F](#) [MLPS-B-3-0408-CC-6-PLP1-313-F](#) [MLPS-B-3-0409-CC-6-PLP1-830-F](#) [MLPS-B-3-0410-CC-8-PLP1-10MM-F](#) [MLPS-B-3-0411-CC-8-PLP1-250-F](#) [MLPS-B-3-0412-CC-8-PLP1-5MM-F](#) [MLPS-B-3-0413-CC-10-PLP1-500-F](#) [MLPS-B-3-0502-CC-2-PLP1-250-F](#) [MLPS-B-3-0509-CC-8-PLP1-7MM-F](#) [MLPS-B-3-0603-CC-4-PLP1-6MM-F](#) [MLPS-B-3-0604-CC-6-PLP1-9MM-F](#) [MLPS-B-3-0101-C0-2-PLP1-375-F](#) [MLPS-B-3-0107-C0-4-PLP1-750-F](#) [MLPS-B-3-0107-C0-4-PLP1-9MM-F](#) [MLPS-B-3-0109-C0-4-PLP1-750-F](#) [MLPS-B-3-0203-CC-2-PLP1-9MM-F](#) [MLPS-B-3-0204-CC-2-PLP1-188-F](#) [MLPS-B-3-0205-CC-2-PLP1-375-F](#) [MLPS-B-3-0206-CC-2-PLP1-500-F](#) [MLPS-B-3-0208-CC-4-PLP1-375-F](#) [MLPS-B-3-0208-CC-4-PLP1-750-F](#) [MLPS-B-3-0209-CC-4-PLP1-6MM-F](#) [MLPS-B-3-0210-CC-4-PLP1-375-F](#) [MLPS-B-3-0210-CC-4-PLP1-9MM-F](#) [MLPS-B-3-0212-CC-4-PLP1-10MM-F](#) [MLPS-B-3-0212-CC-4-PLP1-830-F](#) [MLPS-B-3-0214-CC-6-PLP1-10MM-F](#) [MLPS-B-3-0214-CC-6-PLP1-625-F](#) [MLPS-B-3-0301-CC-2-PLP1-8MM-F](#) [MLPS-B-3-0302-CC-2-PLP1-830-F](#) [MLPS-B-3-0305-CC-4-PLP1-10MM-F](#) [MLPS-B-3-0306-CC-4-PLP1-350-F](#) [MLPS-B-3-0307-CC-4-PLP1-625-F](#) [MLPS-B-3-0311-CC-6-PLP1-500-F](#) [MLPS-B-3-0313-CC-8-PLP1-500-F](#) [MLPS-B-3-0402-CC-2-PLP1-250-F](#) [MLPS-B-3-0412-CC-8-PLP1-750-F](#) [MLPS-B-3-0414-CC-10-PLP1-750-F](#) [MLPS-B-3-0502-CC-2-PLP1-750-F](#) [MLPS-B-3-0502-CC-2-PLP1-9MM-F](#) [MLPS-B-3-0505-CC-4-PLP1-188-F](#) [MLPS-B-3-0506-CC-6-PLP1-375-F](#) [MLPS-B-3-0508-CC-8-PLP1-10MM-F](#) [MLPS-B-3-0509-CC-8-PLP1-188-F](#) [MLPS-B-3-0510-CC-8-PLP1-10MM-F](#) [MLPS-B-3-0510-CC-8-PLP1-830-F](#) [MLPS-B-3-0511-CC-8-PLP1-188-F](#) [MLPS-B-3-0512-CC-10-PLP1-10MM-F](#) [MLPS-B-3-0512-CC-10-PLP1-](#)

[313-F](#) [MLPS-B-3-0512-CC-10-PLP1-625-F](#) [MLPS-B-3-0512-CC-10-PLP1-830-F](#) [MLPS-B-3-0513-CC-10-PLP1-350-F](#)  
[MLPS-B-3-0514-CC-10-PLP1-313-F](#) [MLPS-B-3-0602-CC-4-PLP1-313-F](#) [MLPS-B-3-0606-CC-6-PLP1-375-F](#) [MLPS-B-](#)  
[3-0607-CC-8-PLP1-6MM-F](#) [MLPS-B-3-0608-CC-8-PLP1-188-F](#) [MLPS-B-3-0609-CC-10-PLP1-350-F](#) [MLPS-B-3-0609-](#)  
[CC-10-PLP1-375-F](#) [MLPS-B-3-0610-CC-10-PLP1-350-F](#) [MLPS-B-3-0611-CC-10-PLP1-5MM-F](#) [MLPS-B-3-0613-CC-](#)  
[14-PLP1-10MM-F](#) [MLPS-B-3-0613-CC-14-PLP1-313-F](#) [MLPS-B-3-0614-CC-14-PLP1-313-F](#) [MLPS-B-3-0614-CC-14-](#)  
[PLP1-350-F](#)