
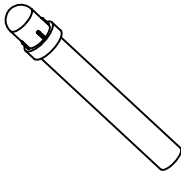
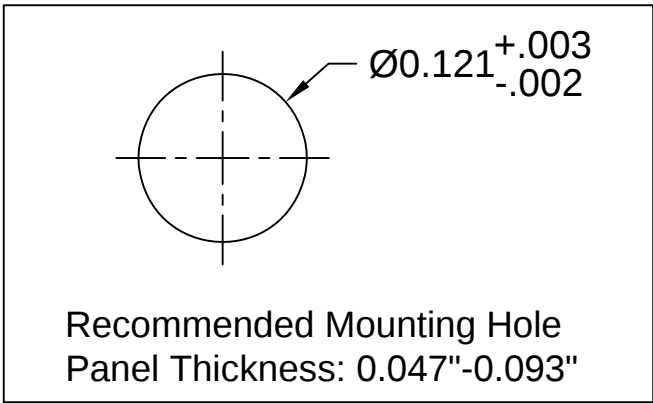


Part No.	X = Body Length
PLP1-100	0.100 (2.5mm)
PLP1-125	0.125 (3.2mm)
PLP1-175	0.175 (4.4mm)
PLP1-188	0.188 (4.8mm)
PLP1-200	0.200 (5.1mm)
PLP1-250	0.250 (6.4mm)
PLP1-313	0.313 (7.9mm)
PLP1-350	0.350 (8.9mm)
PLP1-375	0.375 (9.5mm)
PLP1-460	0.460 (11.7mm)
PLP1-500	0.500 (12.7mm)
PLP1-625	0.625 (15.9mm)
PLP1-750	0.750 (19.0mm)
PLP1-3MM	3mm (0.118")
PLP1-4MM	4mm (0.157")
PLP1-5MM	5mm (0.197")
PLP1-6MM	6mm (0.236")
PLP1-7MM	7mm (0.276")
PLP1-8MM	8mm (0.315")
PLP1-9MM	9mm (0.354")
PLP1-10MM	10mm (0.394")

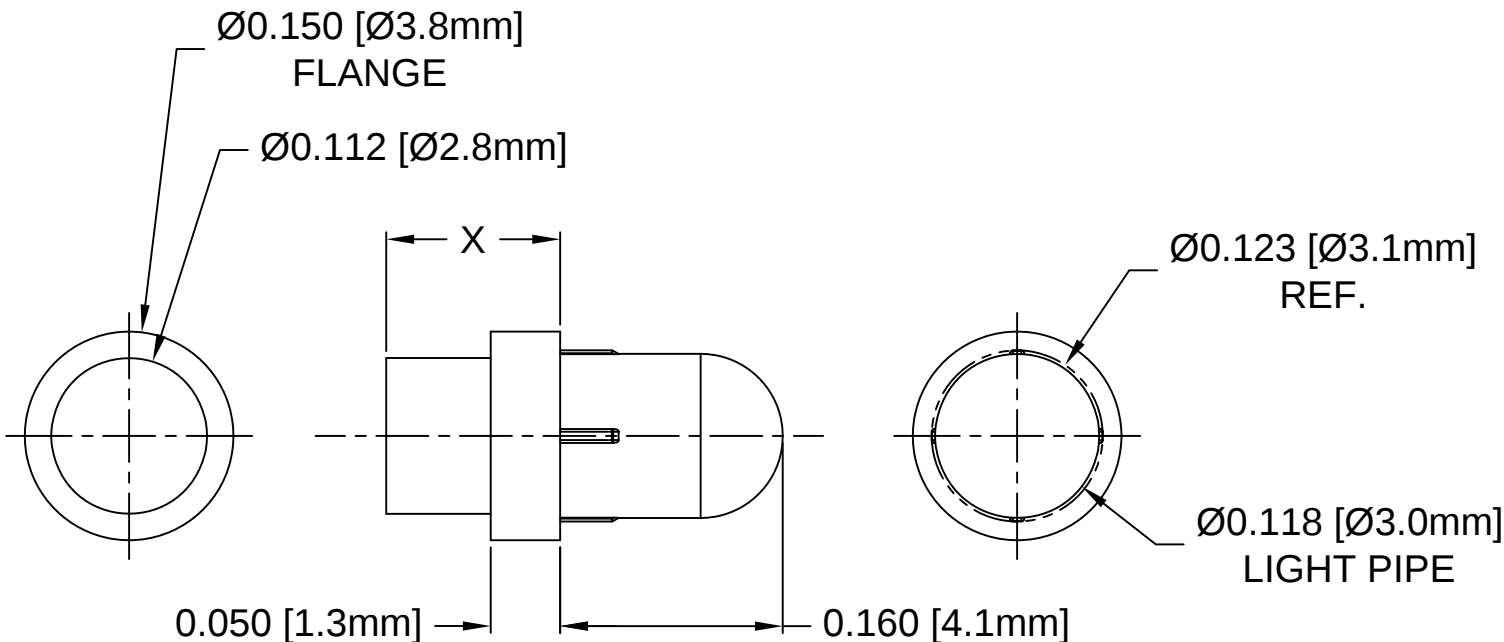

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		BIVAR®	
DECIMALS	ANGULAR	4 THOMAS, IRVINE, CA. 92618	
.X ± .1	X° ± 1°	TEL.: (949) 951-8808 FAX: (949) 951-3974	
.XX ± .01		TITLE: PRESS-FIT, PANEL MOUNT, LIGHT PIPE, ROUND TOP	
.XXX ± .005			
DESIGNED: Michael Chen	DATE: 01/16/02	PART NO: PLP1-XXX	REVISION: T
CHECKED: E. M. Muldoon	DATE: 04/26/02	CAGE CODE : 32559	SHEET # 1 OF 2
CAD GENERATED DOCUMENT. DO NOT MEASURE DRAWING.			

2. MATERIAL: POLYCARBONATE, 94V-0, CLEAR.
1. GENERAL SPECIFICATIONS: BIVAR MOLDED COMPONENT SPECIFICATION BV00-E101 and BSMC-1001.

* SEE TABLE FOR ORDERING INFORMATION

REV.	DESCRIPTION	DATE	APPROVED
	SEE SHEET #1		

PLP1 -

RIGID LIGHT PIPE SERIES

LENGTH

COLOR	Order Code
BLUE	BE
BLACK	BK
GREEN	GN
GRAY	GY
RED	RD
YELLOW	YW

NOTE: LEAVE ORDER CODE BLANK
IF NO COLOR IS DESIRED.

3. PARTS ARE DYED TO COLOR UPON REQUEST.

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED) <u>DECIMALS</u> <u>ANGULAR</u>		 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
		TITLE: PRESS-FIT, PANEL MOUNT, LIGHT PIPE, ROUND TOP	
DESIGNED: K. Aukshunas	DATE: 01/22/16	PART NO: PLP1-XXX	REVISION: T
CHECKED: J. Chiang	DATE: 01/22/16	CAGE CODE : 32559 SHEET # 2 OF 2 CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING.	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[PLP1-125](#) [PLP1-250](#) [PLP1-375](#) [PLP1-500](#) [PLP1-625](#) [PLP1-750](#) [PLP1-625-F](#) [PLP1-125 BE](#) [PLP1-125 GN](#) [PLP1-125 GY](#) [PLP1-125 RD](#) [PLP1-125 YW](#) [PLP1-175](#) [PLP1-200](#) [PLP1-250 BE](#) [PLP1-250 GN](#) [PLP1-250 RD](#) [PLP1-250 YW](#) [PLP1-350](#) [PLP1-350 BE](#) [PLP1-350 GN](#) [PLP1-350 RD](#) [PLP1-350 YW](#) [PLP1-375 BE](#) [PLP1-375 GN](#) [PLP1-375 RD](#) [PLP1-375 YW](#) [PLP1-460](#) [PLP1-500 BE](#) [PLP1-500 GN](#) [PLP1-500 RD](#) [PLP1-500 YW](#) [PLP1-625 BE](#) [PLP1-625 GN](#) [PLP1-625 RD](#) [PLP1-625 YW](#) [PLP1-750 BE](#) [PLP1-750 GN](#) [PLP1-750 RD](#) [PLP1-750 YW](#)